

- For use with RPP5 belt
- Pitch: 5mm
- Material:
Aluminium or phosphated
steel depending on size

Supplied with
pilot bore





Accessories

- Belts RPP5
- Belt tension roller GTC

Info.

- **Pilot bore dimension is given as a guide only may vary between batches
- To be finished to size by customer
- **We are unable to modify these parts.**

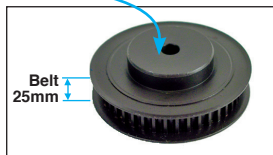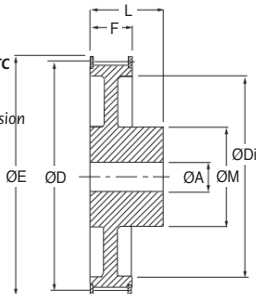

DISCOUNTS

Qty	1+	6+	20+
Disc.	List	-12%	On request

Part number	Material	No. of teeth	PCD Ø external	flange ØE	ØM	ØDi	F	L	Pilot bore **ØA	Price each 1 to 5	
12HTD5M-25F	Steel	12	19,10	17,96	23,0	13,0	-	30,5	36	-	8,18 €
14HTD5M-25F		14	22,28	21,14	25,0	13,0	-	30,5	36	6	8,80 €
15HTD5M-25F		15	23,87	22,73	28,0	16,0	-	30,5	36	6	9,18 €
16HTD5M-25F		16	25,46	24,32	28,0	16,5	-	30,5	36	6	9,59 €
18HTD5M-25F		18	28,65	27,51	32,0	20,0	-	30,5	36	6	10,00 €
20HTD5M-25F		20	31,83	30,69	36,0	23,0	-	30,5	36	6	10,90 €
21HTD5M-25F		21	33,42	32,28	38,0	24,0	-	30,5	38	6	11,23 €
22HTD5M-25F		22	35,01	33,87	39,0	25,5	-	30,5	38	6	12,00 €
24HTD5M-25F		24	38,20	37,06	42,0	27,0	-	30,5	38	6	13,21 €
26HTD5M-25F		26	41,38	40,24	44,0	30,0	-	30,5	38	6	13,95 €
28HTD5M-25F		28	44,56	43,42	48,0	30,5	-	30,5	38	6	15,07 €
30HTD5M-25F		30	47,75	46,60	51,0	35,0	-	30,5	38	6	16,40 €
32HTD5M-25F	32	50,93	49,79	54,0	38,0	-	30,5	38	8	17,40 €	
36HTD5M-25F	36	57,30	56,16	60,0	38,0	-	30,5	38	8	18,22 €	
40HTD5M-25F	40	63,66	62,52	71,0	38,0	-	30,5	38	8	20,96 €	
44HTD5M-25	Aluminium	44	70,03	68,89	-	38,0	-	30,5	40	8	29,26 €
48HTD5M-25		48	76,39	75,25	-	38,0	061	30,5	40	8	34,02 €
60HTD5M-25		60	95,49	94,35	-	50,0	080	30,5	40	8	46,33 €
72HTD5M-25		72	114,59	113,45	-	50,0	100	30,5	40	8	65,06 €

*Depending on availability - Dimensions in mm

Our other products



PW_PWG3
Worm - precision range, Stainless steel



BAN
Angular clamp, Universal



TMR
Rigid manual tensioner, Adjustable



PW_PWG1
Worm - precision range, Stainless steel




BDP1R
Adjustable support arm, Single clamp



M1
Worm and wheel set, Bronze



 GE1006
Elastic ringed latch, Hooks into a slot




PM4
Worm and wheel set, Machined plastic (delrin)



CHMR90
Worm and wheel gear reducer, up to 540 Nm



 PRES
Manual workbench press accessory for PRES-3HR end




BLHM20
Right angled gearbox, double output shafts, up to 1.77 Nm



HBM
Adjustment bushing for half-rail guide, Adjustment bushing

 Complementary products



RPP5
RPP heavy duty timing belt, RPP5



GTC
Belt tensioner, For standard applications