

- For use with RPP5 belt
- Pitch: 5mm
- Material:
Aluminium or phosphated steel depending on size

Supplied with pilot bore





Accessories

- Belts RPP5
- Belt tension roller GTC

Info.

- **Pilot bore dimension is given as a guide only may vary between batches
- To be finished to size by customer
- **We are unable to modify these parts.**

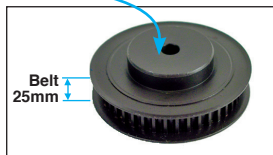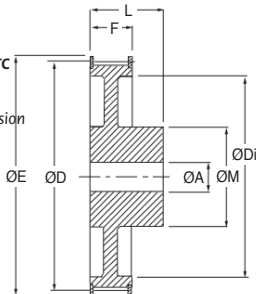

DISCOUNTS

Qty	1+	6+	20+
Disc.	List	-12%	On request

Part number	Material	No. of teeth	PCD external Ø	flange OE	OM	ØDi	F	L	Pilot bore **OA	Price each 1 to 5	
12HTD5M-25F	Steel	12	19,10	17,96	23,0	13,0	-	30,5	36	-	8,18 €
14HTD5M-25F		14	22,28	21,14	25,0	13,0	-	30,5	36	6	8,80 €
15HTD5M-25F		15	23,87	22,73	28,0	16,0	-	30,5	36	6	9,18 €
16HTD5M-25F		16	25,46	24,32	28,0	16,5	-	30,5	36	6	9,59 €
18HTD5M-25F		18	28,65	27,51	32,0	20,0	-	30,5	36	6	10,00 €
20HTD5M-25F		20	31,83	30,69	36,0	23,0	-	30,5	36	6	10,90 €
21HTD5M-25F		21	33,42	32,28	38,0	24,0	-	30,5	38	6	11,23 €
22HTD5M-25F		22	35,01	33,87	39,0	25,5	-	30,5	38	6	12,00 €
24HTD5M-25F		24	38,20	37,06	42,0	27,0	-	30,5	38	6	13,21 €
26HTD5M-25F		26	41,38	40,24	44,0	30,0	-	30,5	38	6	13,95 €
28HTD5M-25F		28	44,56	43,42	48,0	30,5	-	30,5	38	6	15,07 €
30HTD5M-25F		30	47,75	46,60	51,0	35,0	-	30,5	38	6	16,40 €
32HTD5M-25F		32	50,93	49,79	54,0	38,0	-	30,5	38	8	17,40 €
36HTD5M-25F		36	57,30	56,16	60,0	38,0	-	30,5	38	8	18,22 €
40HTD5M-25F	40	63,66	62,52	71,0	38,0	-	30,5	38	8	20,96 €	
44HTD5M-25	Aluminium	44	70,03	68,89	-	38,0	-	30,5	40	8	29,26 €
48HTD5M-25		48	76,39	75,25	-	38,0	061	30,5	40	8	34,02 €
60HTD5M-25		60	95,49	94,35	-	50,0	080	30,5	40	8	46,33 €
72HTD5M-25		72	114,59	113,45	-	50,0	100	30,5	40	8	65,06 €

*Depending on availability - Dimensions in mm


Our other products



PM2
Worm and wheel set,
Bronze



 RFK38B
Hypoid gearbox -
Stainless steel, up to
200 Nm



SLS
Bearing block for
leadscrew, Fixed
Drylin® bearing block



FF10
Offset spur gear
reducer, from 0.78 to
3.70 Nm



CHTRB
Single and dual
output gearboxes, Up
to 16,5 Nm



PSPD18
Flexible tube handle,
Black PVC



ZBconique
Machined plastic
bevel gear, 1:1



CLR
Straight clevis,
Straight clevis for use
with a male clevis



CCLSS
Stainless steel wire
thimble, Stainless



BAP
Plastic clamping
collar, Ø10 - Ø20




CHM63
Worm and wheel gear
reducer, up to 196



GMK17_BROSSE
Brush strip, Cone-
shaped - brush

 Complementary products



RPP5
RPP heavy duty
timing belt, RPP5



GTC
Belt tensioner, For
standard applications