
 


- Bar stock to be cut to length by the customer
- The overall length is the same as the maximum length
- Material : Steel C40

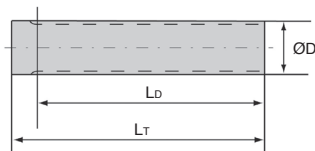

Info.

- We are unable to modify this product



DISCOUNTS

Qty	1+	2+	4+
Disc.	List -20%	On request	

Part number	Z Teeth	ØD External	Length of teeth L _b	Total length L _T	Price each
18HTD8M-BAR	18	44,47	200	200	47,27 €
19HTD8M-BAR	19	47,01	200	200	50,51 €
20HTD8M-BAR	20	49,56	200	200	53,27 €
21HTD8M-BAR	21	52,11	200	200	55,44 €
22HTD8M-BAR	22	54,65	200	200	58,15 €
23HTD8M-BAR	23	57,20	200	200	60,87 €
24HTD8M-BAR	24	59,75	200	200	63,57 €
25HTD8M-BAR	25	62,29	200	200	65,19 €
26HTD8M-BAR	26	64,84	200	200	70,67 €
28HTD8M-BAR	28	69,93	200	200	77,74 €
30HTD8M-BAR	30	75,03	200	200	88,57 €
32HTD8M-BAR	32	80,12	200	200	102,85 €
34HTD8M-BAR	34	85,21	200	200	111,97 €
35HTD8M-BAR	35	87,76	200	200	124,06 €
36HTD8M-BAR	36	90,30	200	200	130,12 €
38HTD8M-BAR	38	95,40	200	200	145,30 €
40HTD8M-BAR	40	100,49	200	200	159,15 €
44HTD8M-BAR	44	110,67	200	200	188,85 €
48HTD8M-BAR	48	120,86	200	200	220,95 €

Dimensions in mm

Our other products



G1

Steel spur gear, Steel
20NCD2



OP3_14_06

Reducing sleeve for
OP indicators,
Reduction socket



BCFH

Mushroom headed
button Hygienic
Usit®, With male
thread and high head



CHAB

Hinge with stop,
Hinge



 
HRV

V- rail guidance
Simple Select®
system, Rail with
carriage



T5-10ECO

T type timing pulley,
Economy range - T5
aluminium



SLVHlok

Vertical toggle clamp,
Vertical toggle clamp /
horizontal foot



WW10

Drylin® W slide, slide
assembly



R205

Die spring ISO10243,
Heavy



GP75

Spring loaded toggle
latch, Standard
(GP75)



TBD

Manual leadscrew
table with opposing
threads, 20kg



BOX-TOR-H

Box set of Nitrile O-
rings in nitrile, 3.00 x
2.00mm to 45.20 x
4.00

Complementary products



HTD5M-BAR

HTD type tooth bar
stock, HTD5