

HTD type timing pulley



Pitch 8mm

Steel or cast iron

Belt width 20mm





- For use with RPP8 belt
- Pitch: 8mm
- Material:
Cast iron or phosphated steel depending on size

Accessories

- Belts RPP8
- Belt tension roller GTC

Info.

- **Pilot bore dimension is given as a guide only may vary between batches
- To be finished to size by customer
- **We are unable to modify these parts.**

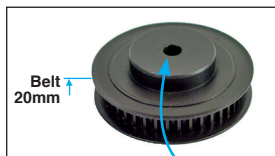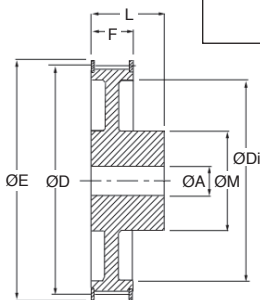

Supplied with pilot bore

DISCOUNTS

| | | | |
|-------|------|------|------------|
| Qty | 1+ | 6+ | 20+ |
| Disc. | List | -12% | On request |

| Part number | Material | No. of teeth | PCD Ø | external ØD | flange OE | ØM | ØDi | F | L | Pilot bore | | Price each 1 to 5 |
|-------------|----------|--------------|--------|-------------|-----------|-----|-----|----|----|------------|---------|-------------------|
| | | | | | | | | | | **ØA | Stock* | |
| 22HTD8M-20F | Steel | 22 | 56,02 | 54,65 | 60,0 | 43 | - | 28 | 38 | 12 | ✓ | 13,03 € |
| 24HTD8M-20F | | 24 | 61,12 | 59,75 | 66,0 | 45 | - | 28 | 38 | 12 | ✓ | 14,47 € |
| 26HTD8M-20F | | 26 | 66,21 | 64,85 | 70,0 | 48 | - | 28 | 38 | 12 | ✓ | 15,45 € |
| 28HTD8M-20F | | 28 | 71,30 | 70,08 | 75,0 | 50 | - | 28 | 38 | 15 | ✓ | 17,13 € |
| 30HTD8M-20F | | 30 | 76,39 | 75,13 | 82,5 | 55 | - | 28 | 38 | 15 | ✓ | 19,65 € |
| 32HTD8M-20F | | 32 | 81,49 | 80,16 | 87,0 | 60 | - | 28 | 38 | 15 | ✓ | 21,69 € |
| 34HTD8M-20F | | 34 | 86,58 | 85,22 | 91,0 | 66 | - | 28 | 38 | 15 | ✓ | 24,13 € |
| 36HTD8M-20F | | 36 | 91,67 | 90,30 | 97,0 | 70 | - | 28 | 38 | 15 | ✓ | 26,66 € |
| 38HTD8M-20F | | 38 | 96,77 | 95,39 | 102,0 | 75 | - | 28 | 38 | 15 | - | 29,26 € |
| 40HTD8M-20F | | 40 | 101,86 | 100,49 | 106,0 | 75 | - | 28 | 38 | 15 | - | 31,59 € |
| 44HTD8M-20F | | 44 | 112,05 | 110,67 | 120,0 | 75 | - | 28 | 38 | 15 | ✓ | 37,63 € |
| 48HTD8M-20F | | 48 | 122,23 | 120,86 | 128,0 | 75 | - | 28 | 38 | 15 | ✓ | 43,41 € |
| 56HTD8M-20F | | 56 | 142,60 | 141,23 | 150,0 | 80 | 116 | 28 | 38 | 15 | ✓ | 55,50 € |
| 64HTD8M-20F | | 64 | 162,97 | 161,60 | 168,0 | 80 | 137 | 28 | 38 | 15 | ✓ | 68,16 € |
| 72HTD8M-20F | 72 | 183,35 | 181,97 | 192,0 | 80 | 158 | 28 | 38 | 15 | ✓ | 81,92 € | |
| 80HTD8M-20 | Cast | 80 | 203,72 | 202,35 | - | 90 | 180 | 28 | 38 | 15 | - | 77,95 € |
| 90HTD8M-20 | | 90 | 229,18 | 227,81 | - | 90 | 204 | 28 | 38 | 15 | - | 88,78 € |

*Depending on availability - Dimensions in mm

Our other products



F7-E

Multifunction display,
With external sensor



RURp

Fixed castor with
plate, Polyurethane -
Aluminium rim (Free
running)




KSTM

Igubal® pillow block
bearing, Polymer



BAC105

Storage bin, 8mm

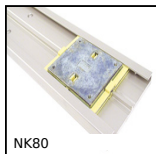

NK80

Drylin®N miniature
guiding system, Width
80mm



BTC_M

End cap with threaded
insert for square tube,
With threaded insert



 
M2

Worm and wheel set,
Machined plastic
(delrin)



GCL

Linear ball slide Eco
Range, economy
range



B

Steel bevel gear, 1:1



CHAEpac

Square decorative
screwed hinges,



CLLCLLP

 
Clevis components,
long version, Steel -



BAGO

Locking rings in steel,
Steel

Complementary products



RPP8

RPP heavy duty
timing belt, RPP8



GTC

Belt tensioner, For
standard applications