

HTD type timing pulley



Pitch 8mm

Steel or cast iron

Belt width 20mm





- For use with RPP8 belt
- Pitch: 8mm
- Material:
Cast iron or phosphated steel depending on size

Accessories

- Belts RPP8
- Belt tension roller GTC

Info.

- **Pilot bore dimension is given as a guide only may vary between batches
- To be finished to size by customer
- **We are unable to modify these parts.**

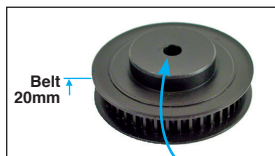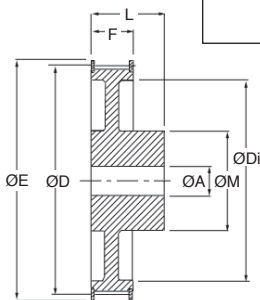

Supplied with pilot bore

DISCOUNTS

Qty	1+	6+	20+
Disc.	List	-12%	On request

Part number	Material	No. of teeth	PCD Ø	external ØD	flange OE	ØM	ØDi	F	L	Pilot bore		Price each 1 to 5
										**ØA	Stock*	
22HTD8M-20F	Steel	22	56,02	54,65	60,0	43	-	28	38	12	✓	13,03 €
24HTD8M-20F		24	61,12	59,75	66,0	45	-	28	38	12	✓	14,47 €
26HTD8M-20F		26	66,21	64,85	70,0	48	-	28	38	12	✓	15,45 €
28HTD8M-20F		28	71,30	70,08	75,0	50	-	28	38	15	✓	17,13 €
30HTD8M-20F		30	76,39	75,13	82,5	55	-	28	38	15	✓	19,65 €
32HTD8M-20F		32	81,49	80,16	87,0	60	-	28	38	15	✓	21,69 €
34HTD8M-20F		34	86,58	85,22	91,0	66	-	28	38	15	✓	24,13 €
36HTD8M-20F		36	91,67	90,30	97,0	70	-	28	38	15	✓	26,66 €
38HTD8M-20F		38	96,77	95,39	102,0	75	-	28	38	15	-	29,26 €
40HTD8M-20F		40	101,86	100,49	106,0	75	-	28	38	15	-	31,59 €
44HTD8M-20F		44	112,05	110,67	120,0	75	-	28	38	15	✓	37,63 €
48HTD8M-20F		48	122,23	120,86	128,0	75	-	28	38	15	✓	43,41 €
56HTD8M-20F		56	142,60	141,23	150,0	80	116	28	38	15	✓	55,50 €
64HTD8M-20F		64	162,97	161,60	168,0	80	137	28	38	15	✓	68,16 €
72HTD8M-20F	72	183,35	181,97	192,0	80	158	28	38	15	✓	81,92 €	
80HTD8M-20	Cast	80	203,72	202,35	-	90	180	28	38	15	-	77,95 €
90HTD8M-20		90	229,18	227,81	-	90	204	28	38	15	-	88,78 €

*Depending on availability - Dimensions in mm

Our other products



CHINV
Invisible hinge,
Invisible - 90° opening



VTSM
Ball head screws
Hygienic Design®,
Stainless steel



MEP
Revolving handle for
handwheel, Fixed



SSB
Stainless steel bevel
gear, 1:1



SUA4
Single chain supplied
by the metre, Steel



STL
Guidance brush - Rail,
Rail



RJA11_27
Sealing strip, Not
clipping



CHA_GC_9SS
Stainless steel garnet
hinge, To be welded



HW_HT
Half-rail guide, Wheel



WJUM20
Drylin® W bearing
block, Slide

 


DILC
Indexing plunger with
cam, with cam



DCG
Suction cup, 2.5
bellows, natural
rubber

Complementary products



RPP8
RPP heavy duty
timing belt, RPP8



GTC
Belt tensioner, For
standard applications