

HTD type timing pulley



Pitch 8mm

Steel or cast iron

Belt width 20mm





- For use with RPP8 belt
- Pitch: 8mm
- Material:
Cast iron or phosphated steel depending on size

Accessories

- Belts RPP8
- Belt tension roller GTC

Info.

- **Pilot bore dimension is given as a guide only may vary between batches
- To be finished to size by customer
- **We are unable to modify these parts.**

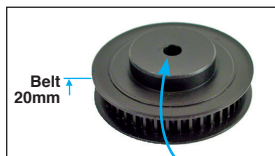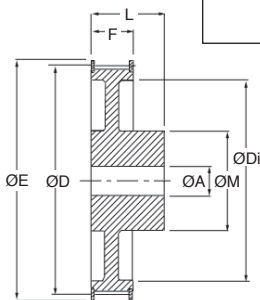

Supplied with pilot bore

DISCOUNTS

Qty	1+	6+	20+
Disc.	List	-12%	On request

Part number	Material	No. of teeth	PCD Ø	external ØD	flange OE	ØM	ØDi	F	L	Pilot bore		Price each 1 to 5
										**ØA	Stock*	
22HTD8M-20F	Steel	22	56,02	54,65	60,0	43	-	28	38	12	✓	13,03 €
24HTD8M-20F		24	61,12	59,75	66,0	45	-	28	38	12	✓	14,47 €
26HTD8M-20F		26	66,21	64,85	70,0	48	-	28	38	12	✓	15,45 €
28HTD8M-20F		28	71,30	70,08	75,0	50	-	28	38	15	✓	17,13 €
30HTD8M-20F		30	76,39	75,13	82,5	55	-	28	38	15	✓	19,65 €
32HTD8M-20F		32	81,49	80,16	87,0	60	-	28	38	15	✓	21,69 €
34HTD8M-20F		34	86,58	85,22	91,0	66	-	28	38	15	✓	24,13 €
36HTD8M-20F		36	91,67	90,30	97,0	70	-	28	38	15	✓	26,66 €
38HTD8M-20F		38	96,77	95,39	102,0	75	-	28	38	15	-	29,26 €
40HTD8M-20F		40	101,86	100,49	106,0	75	-	28	38	15	-	31,59 €
44HTD8M-20F		44	112,05	110,67	120,0	75	-	28	38	15	✓	37,63 €
48HTD8M-20F		48	122,23	120,86	128,0	75	-	28	38	15	✓	43,41 €
56HTD8M-20F		56	142,60	141,23	150,0	80	116	28	38	15	✓	55,50 €
64HTD8M-20F		64	162,97	161,60	168,0	80	137	28	38	15	✓	68,16 €
72HTD8M-20F	72	183,35	181,97	192,0	80	158	28	38	15	✓	81,92 €	
80HTD8M-20	Cast	80	203,72	202,35	-	90	180	28	38	15	-	77,95 €
90HTD8M-20		90	229,18	227,81	-	90	204	28	38	15	-	88,78 €

*Depending on availability - Dimensions in mm

Our other products



NCT
Square tube
connector, Fixed
angle



T5M T10M
T type timing belt per
metre, T5 Steel cored
polyurethane



CLLCLLP
Clevis components,
long version, Steel -
long version



BLHT30
Right angled gearbox,
from 1.65 to 4.40 Nm



DZYSS
Stainless steel
cylindrical stop,
stainless steel



BIM
Indexing plunger mini,
miniature



BPFL
Sheet steel flanged
bearing for light
loads, Sheet steel



 
SLBS
Stainless steel
indexing plunger,
Stainless steel



GGB
Female wing knob,
With blind thread



BPL
Ball transfer unit light
duty, Light




GPLSs
Brush, stainless steel



KB_UU
Closed linear
precision bearing,
Precision - steel

 Complementary products



RPP8
RPP heavy duty
timing belt, RPP8



GTC
Belt tensioner, For
standard applications