

Steel or cast iron

Pitch 8mm

Belt width 30mm

- For use with RPP8 belt
- Pitch: 8mm
- Material:
Cast iron or phosphated steel depending on size

Supplied with pilot bore





Accessories

- Belts RPP8
- Belt tension roller GTC

Info.

- **Pilot bore dimension is given as a guide only may vary between batches
- To be finished to size by customer
- **We are unable to modify these parts.**

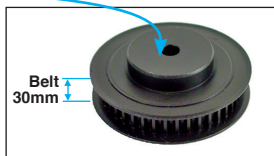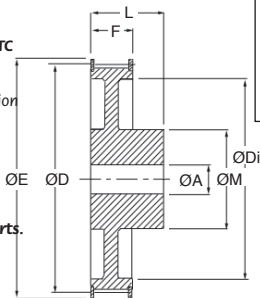

DISCOUNTS

Qty	1+	6+	20+
Disc.	List	-12%	On request

Part number	Material	No. of teeth	PCD Ø	external ØD	flange OE	ØM	ØDi	F	L	Pilot bore **ØA	Stock*	Price each 1 to 5
22HTD8M-30F	Steel	22	56,02	54,65	60,0	43	-	38	48	12	✓	14,57 €
24HTD8M-30F		24	61,12	59,75	66,0	45	-	38	48	12	✓	16,68 €
26HTD8M-30F		26	66,21	64,85	70,0	48	-	38	48	12	✓	18,89 €
28HTD8M-30F		28	71,30	70,08	75,0	50	-	38	48	15	✓	20,96 €
30HTD8M-30F		30	76,39	75,13	82,5	55	-	38	48	15	✓	24,05 €
32HTD8M-30F		32	81,49	80,16	87,0	60	-	38	48	15	-	26,66 €
34HTD8M-30F		34	86,58	85,22	91,0	66	-	38	48	15	✓	29,52 €
36HTD8M-30F		36	91,67	90,30	97,0	70	-	38	48	15	✓	32,60 €
38HTD8M-30F		38	96,77	95,39	102,0	75	-	38	48	15	-	35,86 €
40HTD8M-30F		40	101,86	100,49	106,0	75	-	38	48	15	✓	38,83 €
44HTD8M-30F		44	112,05	110,67	120,0	75	-	38	48	15	-	46,29 €
48HTD8M-30F		48	122,23	120,86	128,0	75	-	38	48	15	✓	53,52 €
56HTD8M-30F		56	142,60	141,23	150,0	90	116	38	48	15	✓	74,57 €
64HTD8M-30F		64	162,97	161,60	168,0	90	137	38	48	15	-	92,14 €
72HTD8M-30F	72	183,35	181,97	192,0	95	158	38	48	15	-	108,21 €	
80HTD8M-30	Cast	80	203,72	202,35	-	100	180	38	48	15	-	96,54 €
90HTD8M-30		90	229,18	227,81	-	100	204	38	48	15	-	105,23 €

*Depending on availability - Dimensions in mm

Our other products



BLHB50

Right angled gearbox, bored shafts, up to 30 Nm



F7-I

Multifunction display, With internal sensor



DOMI50

Accessories, Clamping lever



MDR_SS

Stainless steel Dee shackle with eye bolt, Stainless steel



VPR

Wing screw Hygienic Usit®, Stainless steel



MSP3815

Masterplate® glueable insert rectangular, rectangular with nut



CDP

Flanged drill bushing, Steel



AC

Strike for toggle latch, 12mm



BLM

Spring loaded plunger with ball tip, Plastic body



DER90

Stainless steel AC asynchronous motor 1.1 - 1.5kW, 1.1 to



CMAss


Eye bolt stainless steel, Stainless steel



KB_UU

Closed linear precision bearing, Precision - steel

Complementary products

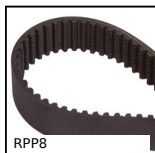

RPP8

RPP heavy duty timing belt, RPP8



GTC

Belt tensioner, For standard applications