

HTD type timing pulley



Pitch 8mm

Steel or cast iron

Belt width 50mm



- For use with RPP8 belt
- Pitch: 8mm
- Material:
Cast iron or phosphated steel
depending on size



Accessories

- Belts RPP8
- Belt tension roller GTC


Info.

- **Pilot bore dimension is given as a guide only may vary between batches
- To be finished to size by customer
- **We are unable to modify these parts.**

Supplied with pilot bore

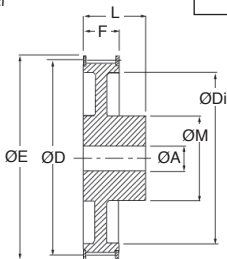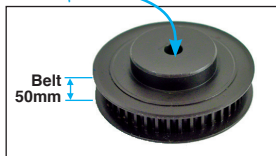

Up to 48 teeth

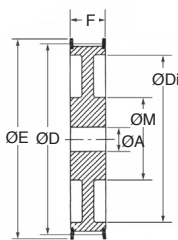

Over more 56 teeth

DISCOUNTS

Qty	1+	6+	20+
Disc.	List	-12%	On request

Part number	Material	No. of teeth	PCD Ø external	ØD flange	ØE	ØM	ØDi	F	L	Pilot bore		Price each
										**ØA	1 to 5	
22HTD8M-50F	Steel	22	56,02	54,65	60,0	43	-	60	70	-	19,95	€
24HTD8M-50F		24	61,12	59,75	66,0	45	-	60	70	-	23,01	€
26HTD8M-50F		26	66,21	64,85	70,0	48	-	60	70	-	26,08	€
28HTD8M-50F		28	71,30	70,08	75,0	50	-	60	70	-	29,42	€
30HTD8M-50F		30	76,39	75,13	82,5	55	-	60	70	-	33,57	€
32HTD8M-50F		32	81,49	80,16	87,0	60	-	60	70	-	37,24	€
34HTD8M-50F		34	86,58	85,22	91,0	66	-	60	70	-	41,44	€
36HTD8M-50F		36	91,67	90,30	97,0	70	-	60	70	-	45,71	€
38HTD8M-50F		38	96,77	95,39	102,0	75	-	60	70	-	50,20	€
40HTD8M-50F		40	101,86	100,49	106,0	75	-	60	70	-	54,57	€
44HTD8M-50F		44	112,05	110,67	120,0	75	-	60	70	-	64,99	€
48HTD8M-50F		48	122,23	120,86	128,0	80	-	60	70	-	75,87	€
56HTD8M-50F		56	142,60	141,23	150,0	90	116	60	60	18	93,29	€
64HTD8M-50F		64	162,97	161,60	168,0	100	137	60	60	18	117,31	€
72HTD8M-50F	72	183,35	181,97	192,0	100	158	60	60	18	144,30	€	
80HTD8M-50	Cast	80	203,72	202,35	-	110	180	60	60	18	130,49	€
90HTD8M-50		90	229,18	227,81	-	110	204	60	60	18	146,24	€

Dimensions in mm

HPC

WEB
04/2020

www.hpceurope.com

Tél: 0 825 88 5000 Service 0,15 €/min + prix appel

Our other products



PT821

Drive sprocket for slat top chain, Ranges 821 and 805



Q3

Double row angular contact ball bearing, Angular contact - Steel



GP75

Spring loaded toggle latch, Standard (GP75)



FGWA

End support, With base



TM_CTM_CTF

Suction cup threaded insert, Insert for suction cup - Tread click-in



BPLF

Ball transfer unit light duty, Light




DOG316

Motor-gearbox 12V and 24V DC, from 1.5 to 2 Nm



BDP1R

 Adjustable support arm, Single clamp



RPPM

RPP type belt per metre, RPP8 Steel cored polyurethane



ACLBMC

Detector support for aluminium profile, Sensor holder



VTSM


Ball head screws Hygienic Design®, Stainless steel



GE32

Sprung toggle latch with connecting link, Standard

 Complementary products



RPP8

RPP heavy duty timing belt, RPP8



GTC

Belt tensioner, For standard applications