

# HTD type timing pulley



## Pitch 8mm

## Steel or cast iron

Belt width 50mm



- For use with RPP8 belt
- Pitch: 8mm
- Material:  
Cast iron or phosphated steel  
depending on size



### Accessories

- Belts RPP8
- Belt tension roller GTC


### Info.

- \*\*Pilot bore dimension is given as a guide only may vary between batches
- To be finished to size by customer
- **We are unable to modify these parts.**

Supplied with pilot bore

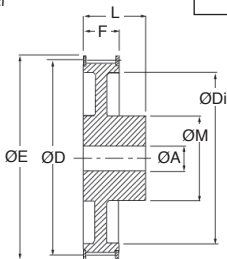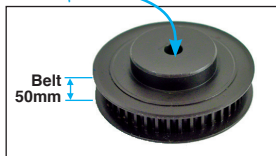

Up to 48 teeth

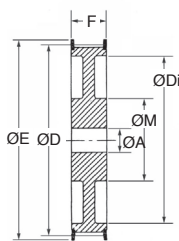

Over more 56 teeth

### DISCOUNTS

Qty	1+	6+	20+
Disc.	List	-12%	On request

Part number	Material	No. of teeth	PCD Ø external	ØD flange	ØE	ØM	ØDi	F	L	Pilot bore Price each	
										**ØA	1 to 5
22HTD8M-50F	Steel	22	56,02	54,65	60,0	43	-	60	70	-	19,95 €
24HTD8M-50F		24	61,12	59,75	66,0	45	-	60	70	-	23,01 €
26HTD8M-50F		26	66,21	64,85	70,0	48	-	60	70	-	26,08 €
28HTD8M-50F		28	71,30	70,08	75,0	50	-	60	70	-	29,42 €
30HTD8M-50F		30	76,39	75,13	82,5	55	-	60	70	-	33,57 €
32HTD8M-50F		32	81,49	80,16	87,0	60	-	60	70	-	37,24 €
34HTD8M-50F		34	86,58	85,22	91,0	66	-	60	70	-	41,44 €
36HTD8M-50F		36	91,67	90,30	97,0	70	-	60	70	-	45,71 €
38HTD8M-50F		38	96,77	95,39	102,0	75	-	60	70	-	50,20 €
40HTD8M-50F		40	101,86	100,49	106,0	75	-	60	70	-	54,57 €
44HTD8M-50F		44	112,05	110,67	120,0	75	-	60	70	-	64,99 €
48HTD8M-50F		48	122,23	120,86	128,0	80	-	60	70	-	75,87 €
56HTD8M-50F		56	142,60	141,23	150,0	90	116	60	60	18	93,29 €
64HTD8M-50F		64	162,97	161,60	168,0	100	137	60	60	18	117,31 €
72HTD8M-50F	72	183,35	181,97	192,0	100	158	60	60	18	144,30 €	
80HTD8M-50	Cast	80	203,72	202,35	-	110	180	60	60	18	130,49 €
90HTD8M-50		90	229,18	227,81	-	110	204	60	60	18	146,24 €

Dimensions in mm

HPC

WEB  
04/2020

www.hpceurope.com

Tél: 0 825 88 5000 Service 0,15 €/min + prix appel

## Our other products



TBE12  
Economic mini-table  
with trapezoidal  
leadscrew, 2kg



PAMF100EB  
Articulated foot with  
sheet metal base  
Ø100, Articulated foot



BPFss  
Pressed stainless  
steel flange bearing,  
Stainless steel



SA\_SAKH  
Housing for linear  
bearing, Closed - light  
load



CHMR75  
Worm and wheel gear  
reducer, up to 298  
Nm



PGR  
Folding revolving  
handle for handwheel,  
Folding



VPRA\_M  
Handwheel with  
handle,  
Thermosetting plastic  
- galvanised steel hub



RTE  
Rotex®, jaw coupling,  
Aluminium



 
METC  
Flanged sintered  
bronze bush, Self-  
lubricating sintered



RHTtcss  
High Temperature  
Castor, up to 200kg




J66  
Spur gear coaxial  
gearbox, from 0.90 to  
2.80 Nm - Inline



PM3  
Worm and wheel set,  
Machined plastic  
(delrin)

## Complementary products

 

RPP8  
RPP heavy duty  
timing belt, RPP8



GTC  
Belt tensioner, For  
standard applications