

180° ball and socket joint steel or stainless steel Stock Ste


IBJ Steel/steel or stainless steel/stainless steel contact

IBJss

- In-line ball and socket joint similar to **DIN 71802**
- Body to DIN 71805
- Stem to DIN 71803
- Materials:
 - Zync plated steel
 - Stainless steel 1.4305 (A2 stainless steel)



Steel or
stainless steel

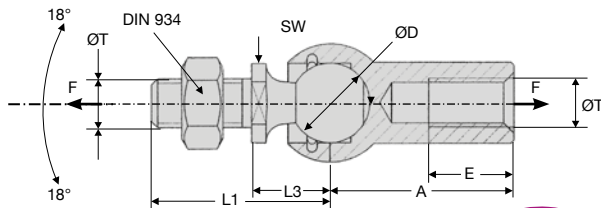

NEW
DISCOUNTS

DISCOUNTS **A** / steel

Qty	1+	6+	20+	40+	60+
Disc.	Price	-20%	-30%	-50%	On request

DISCOUNTS **B** / stainless steel

Qty	1+	6+	20+	40+	60+
Disc.	Price	-15%	-20%	-30%	On request

Part number	ØD	ØT	A	L1	L3	E	SW	Axial load F (N)	Weight (kg)	Stock*	Price each 1 to 5
Steel											
IBJ-5	8	M5	22	19,2	9	10,2	7	30	0,015	✓	A 5,35 €
IBJ-6	10	M6	25	23,5	11	11,5	8	40	0,025	✓	A 6,86 €
IBJ-8	13	M8	30	29,5	13	14,0	11	60	0,053	✓	A 7,25 €
IBJ-10	16	M10	35	36,0	16	15,5	13	80	0,104	✓	A 10,05 €
IBJ-14x1.5	19	M14x1,5	45	48,0	20	21,5	16	100	0,221	✓	A 25,66 €
Stainless Steel											
IBJ-5/SS	8	M5	22	19,2	9	10,2	7	30	0,015	✓	B 9,64 €
IBJ-6/SS	10	M6	25	23,5	11	11,5	8	40	0,025	✓	B 11,55 €
IBJ-8/SS	13	M8	30	29,5	13	14,0	11	60	0,055	✓	B 12,68 €
IBJ-10/SS	16	M10	35	36,0	16	15,5	13	80	0,105	-	B 20,76 €


*Depending on availability - Dimensions in mm

Our other products



TRMSS

Spur round rack,
Stainless steel -
module 1-5

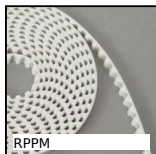

RPPM

RPP type belt per
metre, RPP8 Steel
cored polyurethane



PRS50

Stainless steel
articulated foot Ø50,
Ø 50



CHM40-MOT

Asynchronous AC
motorgearboxes 0.18
to 0.55kW, 0.18 to
0.55kW



AT10-25ECO

AT type timing pulley,
Economy range -
AT10 aluminium



BPHRF

Ball transfer unit
housed spring loaded,
High



PLA

Flat magnet, Flat
magnet



BS2

Panamech, Multi-
Beam, Aluminium -
with set screw



CHN_CHNSS

Straight long link
stainless steel chain,
Stainless steel



BAC105

Storage bin, 8mm



E15

Right angle helical
reducers, from 0.40 to
2.53 Nm



CHTRP

Single and dual
output gearboxes, Up
to 9,1 Nm

Complementary products



RAS

90°ball and socket
joints DIN71802, Steel



IBJss

Ball and socket joint,
Stainless steel



CNA-CNG

Right angled
mounting plate, Right
angled mounting
plate for ball jo...