

# 180° ball and socket joint steel or stainless steel Stock Ste


## IBJ Steel/steel or stainless steel/stainless steel contact

### IBJss

- Inline ball and socket joint similar to DIN 71802
- Body to DIN 71805
- Stem to DIN 71803
- Materials:
  - Zync plated steel
  - Stainless steel 1.4305 (A2 stainless steel)



Steel or  
stainless steel

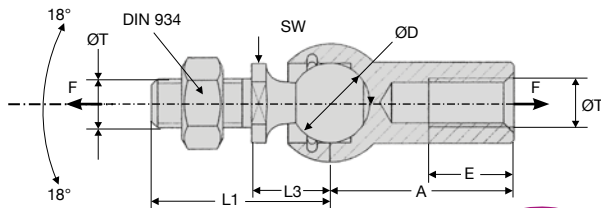

NEW  
DISCOUNTS

### DISCOUNTS **A** / steel

Qty	1+	6+	20+	40+	60+
Disc.	Price	-20%	-30%	-50%	On request

### DISCOUNTS **B** / stainless steel

Qty	1+	6+	20+	40+	60+
Disc.	Price	-15%	-20%	-30%	On request

Part number	ØD	ØT	A	L1	L3	E	SW	Axial load F (N)	Weight (kg)	Stock*	Price each 1 to 5
<b>Steel</b>											
IBJ-5	8	M5	22	19,2	9	10,2	7	30	0,015	✓	<b>A</b> 5,35 €
IBJ-6	10	M6	25	23,5	11	11,5	8	40	0,025	✓	<b>A</b> 6,86 €
IBJ-8	13	M8	30	29,5	13	14,0	11	60	0,053	✓	<b>A</b> 7,25 €
IBJ-10	16	M10	35	36,0	16	15,5	13	80	0,104	✓	<b>A</b> 10,05 €
IBJ-14x1.5	19	M14x1,5	45	48,0	20	21,5	16	100	0,221	✓	<b>A</b> 25,66 €
<b>Stainless Steel</b>											
IBJ-5/SS	8	M5	22	19,2	9	10,2	7	30	0,015	✓	<b>B</b> 9,64 €
IBJ-6/SS	10	M6	25	23,5	11	11,5	8	40	0,025	✓	<b>B</b> 11,55 €
IBJ-8/SS	13	M8	30	29,5	13	14,0	11	60	0,055	✓	<b>B</b> 12,68 €
IBJ-10/SS	16	M10	35	36,0	16	15,5	13	80	0,105	-	<b>B</b> 20,76 €

\*Depending on availability - Dimensions in mm

## Our other products



GLT3E-58

Telescopic drawer,



PLC\_PLT

Magnetic stud with threaded hole, With threaded hole




MRA\_SS

Stainless steel Quick link, Staineless steel



HLA28

 Right angle spiro bevel gearbox, Up to 182Nm



PRF\_PSA

Shaft support for aluminium profile, Shaft support



NT122

Spur gear coaxial gearbox, from 32 to 85 Nm - In-line



ACL-PLAngle

Joining plate for aluminium profile, Angle connection



SCH

Horizontal hook toggle clamp, Horizontal Hook clamp - steel



RPCplss

Swivel castor with double brake, Stainless steel -



PTA150

Articulated levelling foot, pressed base Ø150, Ø 150



BAG0

Locking rings in steel , Steel



RFVcap

Stainless steel protective cover, Open protective cover

## Complementary products



RAS

90° ball and socket joints DIN71802, Steel



IBJss

Ball and socket joint, Stainless steel



CNA-CNG

Right angled mounting plate, Right angled mounting plate for ball jo...