

180° ball and socket joint steel or stainless steel Stock Ste


IBJ Steel/steel or stainless steel/stainless steel contact

IBJss

- In-line ball and socket joint similar to DIN 71802
- Body to DIN 71805
- Stem to DIN 71803
- Materials:
 - Zync plated steel
 - Stainless steel 1.4305 (A2 stainless steel)



Steel or
stainless steel

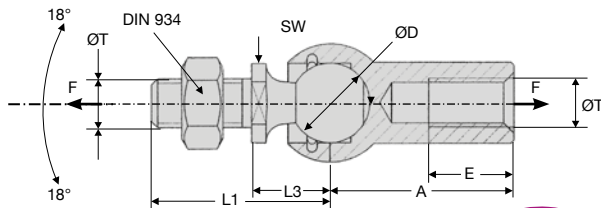

NEW
DISCOUNTS

DISCOUNTS **A** / steel

Qty	1+	6+	20+	40+	60+
Disc.	Price	-20%	-30%	-50%	On request

DISCOUNTS **B** / stainless steel

Qty	1+	6+	20+	40+	60+
Disc.	Price	-15%	-20%	-30%	On request

Part number	ØD	ØT	A	L1	L3	E	SW	Axial load F (N)	Weight (kg)	Stock*	Price each 1 to 5
Steel											
IBJ-5	8	M5	22	19,2	9	10,2	7	30	0,015	✓	A 5,35 €
IBJ-6	10	M6	25	23,5	11	11,5	8	40	0,025	✓	A 6,86 €
IBJ-8	13	M8	30	29,5	13	14,0	11	60	0,053	✓	A 7,25 €
IBJ-10	16	M10	35	36,0	16	15,5	13	80	0,104	✓	A 10,05 €
IBJ-14x1.5	19	M14x1,5	45	48,0	20	21,5	16	100	0,221	✓	A 25,66 €
Stainless Steel											
IBJ-5/SS	8	M5	22	19,2	9	10,2	7	30	0,015	✓	B 9,64 €
IBJ-6/SS	10	M6	25	23,5	11	11,5	8	40	0,025	✓	B 11,55 €
IBJ-8/SS	13	M8	30	29,5	13	14,0	11	60	0,055	✓	B 12,68 €
IBJ-10/SS	16	M10	35	36,0	16	15,5	13	80	0,105	-	B 20,76 €

*Depending on availability - Dimensions in mm

Our other products



 
CHMX_CHMDX

Shaft for worm and wheel reducer CHMR and CHM, CHMR and CHM gearbox...



PRF-SCREEN-1

Screen support, Basic support



RPPM

RPP type belt per metre, RPP8 Steel cored polyurethane



PR881

Idler sprocket for slat top chain, Range 881



SUPss

Self-centering clamping hub stainless steel, Without locknut



PO

Pull handle - Multi-sector, Tapped recessed insert



LOQ

Manual lock, Manual latch



CLB_M

Die cast zinc clamping lever - female, Zamak



MAX22

Motor-gearbox 12V and 24V DC, from 0,07 to 0,2Nm



CAP880

Side flexing slim slat top chain acetal, Narrow range 880



PSG25

Spur gear - precision range, Pre-hardened Steel 35NCD6



ACL-FPA

Panel mounting block for aluminium structures, Support block

Complementary products



RAS

90°ball and socket joints DIN71802, Steel



IBJss

Ball and socket joint, Stainless steel



CNA-CNG

Right angled mounting plate, Right angled mounting plate for ball jo...