

180° ball and socket joint steel or stainless steel Stock Ste

IBJ Steel/steel or stainless steel/stainless steel contact

IBJss

- **Inline ball and socket joint similar to DIN 71802**

- Body to DIN 71805

- Stem to DIN 71803


- Materials:

Zync plated steel

Stainless steel 1.4305 (A2 stainless steel)



Steel or
stainless steel

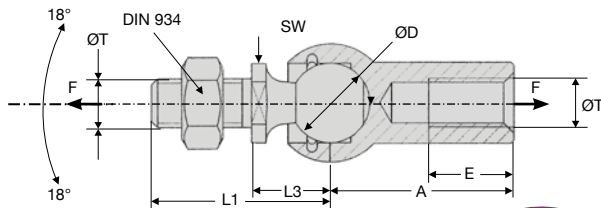

NEW
DISCOUNTS

DISCOUNTS **A** / steel

Qty	1+	6+	20+	40+	60+
Disc.	Price	-20%	-30%	-50%	On request

DISCOUNTS **B** / stainless steel

Qty	1+	6+	20+	40+	60+
Disc.	Price	-15%	-20%	-30%	On request

Part number	ØD	ØT	A	L1	L3	E	SW	Axial load F (N)	Weight (kg)	Stock*	Price each 1 to 5
Steel											
IBJ-5	8	M5	22	19,2	9	10,2	7	30	0,015	✓	A 5,35 €
IBJ-6	10	M6	25	23,5	11	11,5	8	40	0,025	✓	A 6,86 €
IBJ-8	13	M8	30	29,5	13	14,0	11	60	0,053	✓	A 7,25 €
IBJ-10	16	M10	35	36,0	16	15,5	13	80	0,104	✓	A 10,05 €
IBJ-14x1.5	19	M14x1,5	45	48,0	20	21,5	16	100	0,221	✓	A 25,66 €
Stainless Steel											
IBJ-5/SS	8	M5	22	19,2	9	10,2	7	30	0,015	✓	B 9,64 €
IBJ-6/SS	10	M6	25	23,5	11	11,5	8	40	0,025	✓	B 11,55 €
IBJ-8/SS	13	M8	30	29,5	13	14,0	11	60	0,055	✓	B 12,68 €
IBJ-10/SS	16	M10	35	36,0	16	15,5	13	80	0,105	-	B 20,76 €

*Depending on availability - Dimensions in mm

Our other products



ACLLPP

Latch for aluminium profile, Spring operated latch



PRF_SDD

Support for Ø12mm Prox detector, Ø12



YG4

HEAVY DUTY spur gear, Steel 35NCD6



PLN

Cylindrical spacer, Thermoplastic



P70

Worm and wheel gear reducer, up to 164 Nm



RUR

Wheel, Polyurethane - Aluminium rim (Free running)



H2

Crossed helical gear crossed axis at 90°, Machined plastic (delrin)



WJUM16

Drylin® W bearing block, Slide



CHM63

Worm and wheel gear reducer, up to 196 Nm



RPCtcss

Swivel castor with central hole, Stainless



DOMI120

Accessories, Turntable



DKONSL

Silicon conical elasto buffer, Male mounting

Complementary products



RAS

90° ball and socket joints DIN71802, Steel



IBJss

Ball and socket joint, Stainless steel



CNA-CNG

Right angled mounting plate, Right angled mounting plate for ball jo...