

# Internal gear



## Module


Steel or **machined** plastic

0,4   
1,0 

- Pressure angle 20°
- Materials:  
steel 20NCD2 or  
delrin plastic (machined parts)


### Accessories

- Spur gears with the same module ex  
G0,4..., ZG0,4..., G1, ZG1...

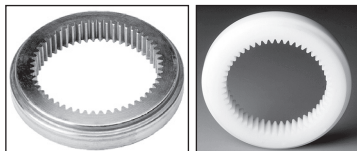

IN : Steel

ZIN : Delrin

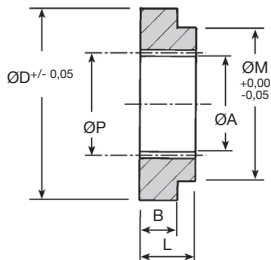

### DISCOUNT Steel

Qty	1+	6+	20+	40+
Disc.	List -12%	-25%	On request	

### DISCOUNT Delrin

Qty	1+	6+	30+
Disc.	List -22%	On request	

Part number		Z	PCD	Internal		Boss		Price each 1 to 5		
Steel IN	Delrin ZIN	teeth	ØP	ØA	ØD	L	B	ØM	Steel IN	Delrin ZIN
<b>Module 0.4</b>										
IN0.4-100	ZIN0.4-100	100	40	39,2	60	5	3	55	56,26 €	40,49 €
IN0.4-120	ZIN0.4-120	120	48	47,2	75	5	3	70	62,95 €	45,22 €
IN0.4-150	ZIN0.4-150	150	60	53,2	75	5	3	70	71,75 €	51,58 €
IN0.4-200	ZIN0.4-200	200	80	79,2	125	5	3	100	95,45 €	68,64 €
<b>Module 1.0</b>										
IN1-58	ZIN1-58	58	58	56	100	11	8	94	75,97 €	54,71 €
IN1-60	ZIN1-60	60	60	58	100	11	8	94	76,97 €	55,39 €
IN1-100	ZIN1-100	100	100	98	150	11	8	125	132,10 €	95,08 €

Dimensions in mm


## Our other products



PRF\_BM  
Base support plate for aluminium profile,  
Central base fixation



 
PARF110  
Pressed steel base rigid foot, Swivelling  
Ø110



B  
Steel bevel gear, 1:1



 SVG  
Adjustable latch clamp with strike plate, Stroke from  
118mm to 130,5mm



B  
Steel bevel gear, 1:1



PTA50  
Articulated levelling foot, pressed base  
Ø50, Ø 50




MDR  
Dee shackle with eye bolt, Steel



SH0  
Parallel axis helical gear, Steel 20NCD2



 CLSCLP\_SS  
Clevis components, short version,



RPP14  
RPP heavy duty timing belt, RPP14



PSG08S  
Spur gear - precision range, Stainless steel



VTLM  
3 lobed handle, Polyamide - Steel

## Complementary products



INO  
Internal gear, Steel 20NCD2



ZG0  
Plastic spur gear, Machined plastic (delrin)