

Internal gear



Module


Steel or **machined** plastic

0,4 
1,0 

- Pressure angle 20°
- Materials:
steel 20NCD2 or
delrin plastic (machined parts)


Accessories

- Spur gears with the same module ex
G0,4..., ZG0,4..., G1, ZG1...

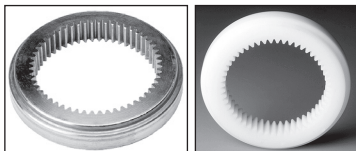

IN : Steel

ZIN : Delrin

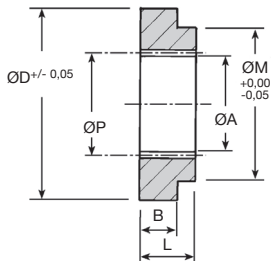

DISCOUNT Steel

Qty	1+	6+	20+	40+
Disc.	List -12%	-25%	On request	

DISCOUNT Delrin

Qty	1+	6+	30+
Disc.	List -22%	On request	

Part number		Z	PCD	Internal		Boss		Price each 1 to 5		
Steel IN	Delrin ZIN	teeth	ØP	ØA	ØD	L	B	ØM	Steel IN	Delrin ZIN
Module 0.4										
IN0.4-100	ZIN0.4-100	100	40	39,2	60	5	3	55	56,26 €	40,49 €
IN0.4-120	ZIN0.4-120	120	48	47,2	75	5	3	70	62,95 €	45,22 €
IN0.4-150	ZIN0.4-150	150	60	53,2	75	5	3	70	71,75 €	51,58 €
IN0.4-200	ZIN0.4-200	200	80	79,2	125	5	3	100	95,45 €	68,64 €
Module 1.0										
IN1-58	ZIN1-58	58	58	56	100	11	8	94	75,97 €	54,71 €
IN1-60	ZIN1-60	60	60	58	100	11	8	94	76,97 €	55,39 €
IN1-100	ZIN1-100	100	100	98	150	11	8	125	132,10 €	95,08 €

Dimensions in mm

Our other products



BPPL

Assembly tool for carrier ball, Mounting tool



BIMSS

Indexing plunger mini, miniature - Stainless steel



 
JSM

Cylindrical polymer bush, Universal polymer



CHTRB

Single and dual output gearboxes, Up to 16,5 Nm



H2

Crossed helical gear crossed axis at 90°, Machined plastic (delrin)



BKGS

Backlash free coupling Gerwah®, from 1.2 to 450Nm



SHS

Shoulder screw stainless steel 303, Stainless steel 303



PCS50

Chain sprocket - steel, 12.7mm (DIN08B-1)



LFM2

Steel leadscrew, Medium carbon steel - 2 threads



SVR30

Screwjack with travelling nut, with moving nut



SLBW

 
Indexing plunger, weldable, Weldable - Steel



PPF

Indexing plunger with flange, with drilled flange

Complementary products



INO

Internal gear, Machined plastic (delrin)



G0

Steel spur gear, Steel 20NCD2