

Steel or **machined** plastic

MODULE
1.25

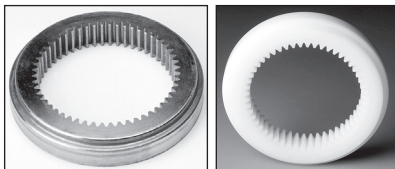

- Pressure angle 20°
- Materials:
steel 34C10 or
delrin plastic (machined parts)

Options

- Alternative number of teeth (minimum 58 teeth)
- Alternative materials (stainless steel, brass..)


Accessories

- Spur gears with the same module eg G1.25.., ZG1.25..



IN: Steel

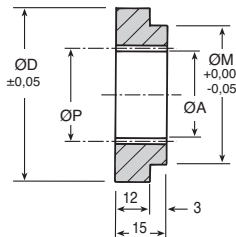ZIN: Plastic



STEEL DISCOUNTS

Qty.	1+	6+	20+	40+
Disc.	List -12%	-25%	On request	

PLASTIC DISCOUNTS

Qty.	1+	6+	30+
Disc.	List -12%	-22%	On request

STEEL IN	PLASTIC ZIN	Z Teeth	PCD ØP	Part number Internal		Boss ØM	Price each 1 to 5	
				ØA	ØD		STEEL IN	PLASTIC ZIN
IN1.25-51	ZIN1.25-51	51	63,75	61,75	100	94	62,55 €	45,04 €
IN1.25-60	ZIN1.25-60	60	75,00	72,50	100	94	67,05 €	48,28 €
IN1.25-100	ZIN1.25-100	100	125,00	122,50	175	150	117,31 €	84,46 €
Gears available up to this size								
IN1,25-160	ZIN1,25-160	160	200,00	197,50	250	225	on request	on request

Dimensions in mm

Our other products



PC56255

Chain sprocket -
Stainless steel,
15.875mm (DIN
08B-1)



PSG1255

Spur gear - precision
range, Stainless steel
303



GG3

Ground spur gear,
Heat treated steel



UGH20

H Type Guide units,
For Ø20 actuators



TB8

Cylindrical roller
thrust bearing, Steel



GLT2-17

Telescopic drawer
runners for groove
mounting, Partial
extension



PITAss

Locking bolt, with T
handle



G01

Single universal joint,
Normal duty



NT61

Spur gear coaxial
gearbox, from 5 to 14
Nm - Inline



BCTH

Mushroom headed
button Hygienic
Usit®, With female



PCP

Cell carrier assembly,
Ready assembled



BPVM

Miniature ball transfer
unit, Miniature to
screw

Complementary products



ZG125

Plastic spur gear,
Machined plastic
(delrin)