

Steel or **machined** plastic

MODULE  
**1.25**  
**E**


- Pressure angle 20°
- Materials:  
steel 34C10 or  
delrin plastic (machined parts)

### Options

- Alternative number of teeth (minimum 58 teeth)
- Alternative materials (stainless steel, brass..)


### Accessories

- Spur gears with the same module eg G1.25.., ZG1.25..

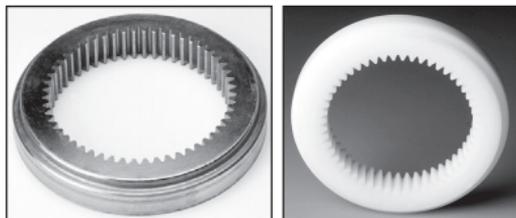

IN: Steel

ZIN: Plastic

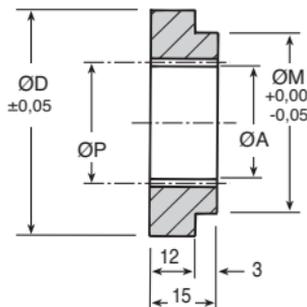

### STEEL DISCOUNTS

|       |           |      |            |     |
|-------|-----------|------|------------|-----|
| Qty.  | 1+        | 6+   | 20+        | 40+ |
| Disc. | List -12% | -25% | On request |     |

### PLASTIC DISCOUNTS

|       |           |            |     |
|-------|-----------|------------|-----|
| Qty.  | 1+        | 6+         | 30+ |
| Disc. | List -22% | On request |     |

| STEEL IN                               | PLASTIC ZIN | Z<br>Teeth | PCD<br>ØP | Part number<br>Internal |     | Boss<br>ØM | Price each 1 to 5 |             |
|----------------------------------------|-------------|------------|-----------|-------------------------|-----|------------|-------------------|-------------|
|                                        |             |            |           | ØA                      | ØD  |            | STEEL IN          | PLASTIC ZIN |
| IN1.25-51                              | ZIN1.25-51  | 51         | 63,75     | 61,75                   | 100 | 94         | 62,55 €           | 45,04 €     |
| IN1.25-60                              | ZIN1.25-60  | 60         | 75,00     | 72,50                   | 100 | 94         | 67,05 €           | 48,28 €     |
| IN1.25-100                             | ZIN1.25-100 | 100        | 125,00    | 122,50                  | 175 | 150        | 117,31 €          | 84,46 €     |
| <b>Gears available up to this size</b> |             |            |           |                         |     |            |                   |             |
| IN1,25-160                             | ZIN1,25-160 | 160        | 200,00    | 197,50                  | 250 | 225        | on request        | on request  |

Dimensions in mm

## Our other products



Stainless steel spur gear, Stainless steel 304L



Idle sprocket for slat top chain, Rangs 820 and 815



Spherical bushing, Hard chromium / PTFE



Tools Hygienic Usit® and Hygienic Design®, Protective inserts for ...



Optional shaft for E-type gear reducers, E Gearboxes double sided ou...



Masterplate® glueable insert Ø19, Cylindrical with tapped insert




Shoulder screw stainless steel 303, Stainless steel 303



Box set of Nitrile O-rings in nitrile, 3.00 x 2.00mm to 45.20 x 4.00



Worm, Non hardened steel

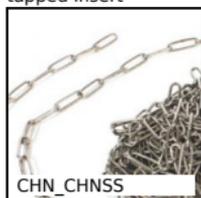

Straight long link stainless steel chain,



Connecting kits, XZ linking kit



Axial thrust bearing, Steel balls

## Complementary products



Plastic spur gear, Machined plastic (delrin)