

Steel or **machined** plastic

MODULE
1.25
E


- Pressure angle 20°
- Materials:
steel 34C10 or
delrin plastic (machined parts)

Options

- Alternative number of teeth (minimum 58 teeth)
- Alternative materials (stainless steel, brass..)


Accessories

- Spur gears with the same module eg G1.25.., ZG1.25..

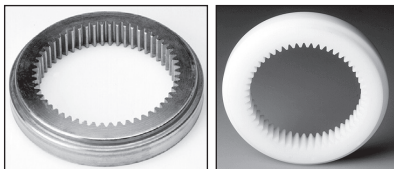

IN: Steel

ZIN: Plastic

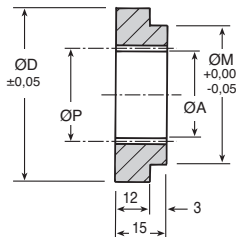

STEEL DISCOUNTS

Qty.	1+	6+	20+	40+
Disc.	List -12%	-25%	On request	

PLASTIC DISCOUNTS

Qty.	1+	6+	30+
Disc.	List -22%	On request	

STEEL IN	PLASTIC ZIN	Z Teeth	PCD ØP	Part number Internal		Boss ØM	Price each 1 to 5	
				ØA	ØD		STEEL IN	PLASTIC ZIN
IN1.25-51	ZIN1.25-51	51	63,75	61,75	100	94	62,55 €	45,04 €
IN1.25-60	ZIN1.25-60	60	75,00	72,50	100	94	67,05 €	48,28 €
IN1.25-100	ZIN1.25-100	100	125,00	122,50	175	150	117,31 €	84,46 €
Gears available up to this size								
IN1,25-160	ZIN1,25-160	160	200,00	197,50	250	225	on request	on request

Dimensions in mm

Our other products



GP

Spring loaded toggle latch, Standard (GP22-GP23)



PSG05

Spur gear - precision range, Case hardened steel 20NCD2



DOMI50

Accessories, Plate



T5M T10M

T type timing belt per metre, T10 Steel cored polyurethane



FAD

Threaded swivel feet, Swivel feet without anti-slip plate



CHTRB

Single and dual output gearboxes, Up to 87,3 Nm



DOMI50

Connecting kits, XY linking kit



SHW

Plain washer, Steel



RT70

Self-centering locking Assembly, Medium/high torque



CHA1056-UPA

Molded polyamide face-mounted hinge, Black polyamide



CLR

Straight clevis, Straight clevis for use with a male clevis



UCFL_SS

Stainless steel flanged bearing, Stainless steel

Complementary products



ZG125

Plastic spur gear, Machined plastic (delrin)