

Steel or **machined** plastic

MODULE
1.25
E


- Pressure angle 20°
- Materials:
steel 34C10 or
delrin plastic (machined parts)

Options

- Alternative number of teeth (minimum 58 teeth)
- Alternative materials (stainless steel, brass..)


Accessories

- Spur gears with the same module eg G1.25.., ZG1.25..

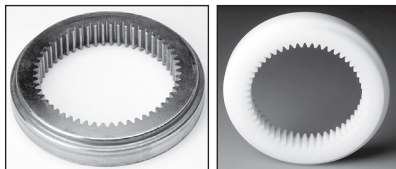

IN: Steel

ZIN: Plastic

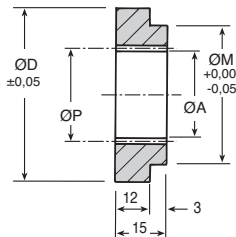

STEEL DISCOUNTS

Qty.	1+	6+	20+	40+
Disc.	List -12%	-25%	On request	

PLASTIC DISCOUNTS

Qty.	1+	6+	30+
Disc.	List -22%	On request	

STEEL IN	PLASTIC ZIN	Z Teeth	PCD ØP	Part number Internal		Boss ØM	Price each 1 to 5	
				ØA	ØD		STEEL IN	PLASTIC ZIN
IN1.25-51	ZIN1.25-51	51	63,75	61,75	100	94	62,55 €	45,04 €
IN1.25-60	ZIN1.25-60	60	75,00	72,50	100	94	67,05 €	48,28 €
IN1.25-100	ZIN1.25-100	100	125,00	122,50	175	150	117,31 €	84,46 €
Gears available up to this size								
IN1,25-160	ZIN1,25-160	160	200,00	197,50	250	225	on request	on request

Dimensions in mm

Our other products



PGM52-M4
Push/Pull handle,
Brass



PTAF80-PAMF80
Articulated fixable
foot with pressed
base Ø80, Ø 80



CHB
Worm and wheel gear
reducer, up to 22 Nm



CFES
Eccentric cam
follower, Eccentric



SHNbr
Hexagonal nut
DIN934, Brass



CFF
Female rod ends DIN
ISO12240-4, Steel /
bronze



H3
Crossed helical gear
crossed axis at 90°,
Steel 20NCD2



ACM_DZ
Clip for bonnet
fastener, Clip



EML
Stainless steel
hexagonal headed
thumb nut, Lobed
handscrew



BLHT20
Right angled gearbox,
from 0.66 to 1.77 Nm



AT5courroie
AT type timing belt,
AT5 Steel cored
polyurethane



METC
Flanged sintered
bronze bush, Self-
lubricating sintered
bronze

Complementary products



ZG125
Plastic spur gear,
Machined plastic
(delrin)