

Steel or **machined** plastic

MODULE
1.25
E


- Pressure angle 20°
- Materials:
steel 34C10 or
delrin plastic (machined parts)

Options

- Alternative number of teeth (minimum 58 teeth)
- Alternative materials (stainless steel, brass..)


Accessories

- Spur gears with the same module eg G1.25.., ZG1.25..

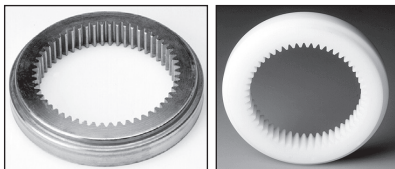

IN: Steel

ZIN: Plastic

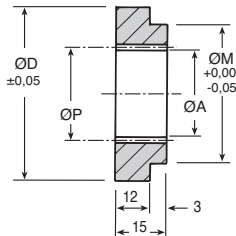

STEEL DISCOUNTS

Qty.	1+	6+	20+	40+
Disc.	List -12%	-25%	On request	

PLASTIC DISCOUNTS

Qty.	1+	6+	30+
Disc.	List -12%	-22%	On request


STEEL IN	PLASTIC ZIN	Z Teeth	PCD ØP	Part number Internal		Boss ØM	Price each 1 to 5	
				ØA	ØD		STEEL IN	PLASTIC ZIN
IN1.25-51	ZIN1.25-51	51	63,75	61,75	100	94	62,55 €	45,04 €
IN1.25-60	ZIN1.25-60	60	75,00	72,50	100	94	67,05 €	48,28 €
IN1.25-100	ZIN1.25-100	100	125,00	122,50	175	150	117,31 €	84,46 €
Gears available up to this size								
IN1,25-160	ZIN1,25-160	160	200,00	197,50	250	225	on request	on request

Dimensions in mm

Our other products



 PC53755
Chain sprocket -
Stainless steel, 9.525
(DIN 06B-1)



PB
Plastic deep groove
ball bearing, Plastic -
glass balls material



SUP
Self-centering
clamping hub steel,
Without locknut



DOMI120
Domino 120
adjustable slide, Slide
DOMILINE 120



MSP3815
Masterplate®
glueable insert
rectangular,
rectangular with nut



DOMI30
Domino 30 adjustable
slide, Slide DOMILINE
30



RPCplss
Swivel castor with
double brake,
Stainless steel -
Polyamide



GCA
Linch pin, Linch



PM4
Worm and wheel set,
Machined plastic



BLHB30
Right angled gearbox,
bored shafts, up to



H2
Crossed helical gear
crossed axis at 90°,



DB
Steel bevel gear, 2:1

Complementary products



ZG125
Plastic spur gear,
Machined plastic
(delrin)