

Steel or **machined** plastic

Module



- Pressure angle 20°
- Materials:
steel 20NCD2 or
delrin plastic (machined parts)

Accessories


- Spur gears with the same module ex
G0,4..., ZG0,4...,G2, ZG2...



IN : Steel



ZIN : Delrin

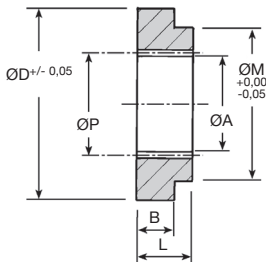

DISCOUNT Steel

Qty	1+	6+	20+	40+
Disc.	List -12%	-25%	On request	

DISCOUNT Delrin

Qty	1+	6+	30+
Disc.	List -22%	On request	

Part number		Z	PCD	Internal	ØD	L	B	Boss ØM	Price each 1 to 5	
Steel IN	Delrin ZIN	teeth	ØP	ØA					Steel IN	Delrin ZIN
Module 1.5										
IN1.5-41	ZIN1.5-41	41	61,5	58	100	15	12	94	86,73 €	62,33 €
IN1.5-60	ZIN1.5-60	60	90,0	87	150	15	12	125	133,33 €	95,90 €
IN1.5-100	ZIN1.5-100	100	150,0	147	200	15	12	175	225,72 €	173,99 €
Module 2.0										
IN2-40	ZIN2-40	40	80	76	150	15	12	125	119,74 €	83,80 €
IN2-60	ZIN2-60	60	120	116	175	15	12	150	186,56 €	130,58 €
IN2-80	ZIN2-80	80	160	156	220	15	12	200	245,54 €	171,85 €
IN2-100	ZIN2-100	100	200	196	250	15	12	220	315,84 €	221,08 €

Dimensions in mm

Our other products



CHN_CHNSS

Straight long link chain, Galvanised steel



CHM40-MOT

Asynchronous AC motorgearboxes 0.18 to 0.55kW, 0.18 to 0.55kW



SBS_L

Chain link, Stainless steel



PW_PWG2

Worm - precision range, Steel



PFC

Fixed rubber levelling foot, Levelling support for small parts



MEF

Cylindrical sintered ferrous bush, Self-lubricating FP20 ferrous all...



PT821

Drive sprocket for slot top chain, Ranges 821 and 805



METEB

Self-lubricating blanks, Bronze BP25



FF10

Offset spur gear reducer, from 0.78 to 3.70 Nm




CHA135

Screwed hinge, 135 degrees



SSB


Stainless steel bevel gear, 1:1

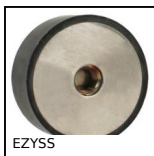

EZYSS

Stainless steel cylindrical stop, stainless steel

Complementary products

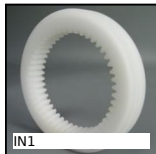

IN1

Internal gear, Machined plastic (delrin)



G1

Steel spur gear, Steel 20NCD2



GG1

Ground spur gear, Heat treated steel