

Internal gear



MODULE

Steel or **machined** plastic

1.0



- Pressure angle 20°
- Materials:
steel 34C10 or
delrin plastic (machined parts)

Options

- Alternative number of teeth
(minimum 58 teeth)
- Alternative materials (stainless
steel, brass..)

Accessories


- Spur gears with the same module
eg G1.., ZG1..



IN: Steel



ZIN: Plastic

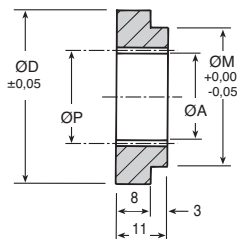

STEEL DISCOUNTS

Qty.	1+	6+	20+	40+
Disc.	List -12%	-25%	On request	

PLASTIC DISCOUNTS

Qty.	1+	6+	30+
Disc.	List -22%	On request	

STEEL IN	PLASTIC ZIN	Z Teeth	PCD ØP	Part number internal ØA	ØD	Boss ØM	Price each 1 to 5	
							STEEL IN	PLASTIC ZIN
IN1-58	ZIN1-58	58	58	56	100	94	60,97 €	43,90 €
IN1-60	ZIN1-60	60	60	58	100	94	61,75 €	44,45 €
IN1-100	ZIN1-100	100	100	98	150	125	105,97 €	76,29 €
Gears available up to this size								
IN1-200	ZIN1-200	200	200	198	250	225	on request	on request

Dimensions in mm

Our other products



NSKB

Drylin® Rail end cap,
Rail end cap



BLHB30

Right angled gearbox,
bored shafts, up to
4.4 Nm



BUT

Panel stop, Panel stop



RPP

Connecting plate for
RPP type timing belts,
RPP8



DOMI50

Domino 50 adjustable
slide, Slide DOMILINE
50



RTTss

Locking assembly,
Medium/high torque




RFK58B

Hypoid gearbox -
Stainless steel, up to
500 Nm



CLSCLP

 Clevis components,
short version, Steel -
Short range



PTR

Idler chain sprocket,
For standard
applications



VTA

Vari-Tork® slip
friction clutch, 0.53 to
1.32 Nm



ESCON

Speed controller 5A, 5
A



BPM-Z

Plastic slotted spring
plunger with ball tip,
Plastic body +
stainle...

Complementary products



IN1

Internal gear, Steel
20NC2



ZG1

Plastic spur gear,
Machined plastic
(delrin)



CLG1

Moulded plastic spur
gear, Moulded plastic
(nylon)