

Internal gear



MODULE

Steel or **machined** plastic

1.0



- Pressure angle 20°
- Materials:
steel 34C10 or
delrin plastic (machined parts)

Options

- Alternative number of teeth
(minimum 58 teeth)
- Alternative materials (stainless
steel, brass..)

Accessories


- Spur gears with the same module
eg G1.., ZG1..



IN: Steel



ZIN: Plastic

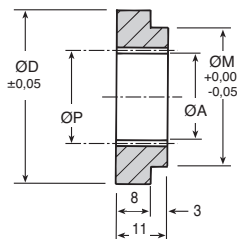

STEEL DISCOUNTS

Qty.	1+	6+	20+	40+
Disc.	List -12%	-25%	On request	

PLASTIC DISCOUNTS

Qty.	1+	6+	30+
Disc.	List -22%	On request	

STEEL IN	PLASTIC ZIN	Z Teeth	PCD ØP	Part number internal ØA	ØD	Boss ØM	Price each 1 to 5	
							STEEL IN	PLASTIC ZIN
IN1-58	ZIN1-58	58	58	56	100	94	60,97 €	43,90 €
IN1-60	ZIN1-60	60	60	58	100	94	61,75 €	44,45 €
IN1-100	ZIN1-100	100	100	98	150	125	105,97 €	76,29 €
Gears available up to this size								
IN1-200	ZIN1-200	200	200	198	250	225	on request	on request

Dimensions in mm

Our other products



ACM_TRI

Manual bonnet fastener, Black rubber fastener



UGH32

H Type Guide units, For Ø32 actuators



G01

Single universal joint, Normal duty



PDD

Actuating plunger, Non-rotating detector shaft



RCX-6

Spherical tilt washer - DIN6319, concave



RBGpl

Swivel castor with plate, Steel - grey rubber



 
SCA

Flat cable clamp, Steel



BPH

Ball transfer unit plain fit, High



RPP5

RPP heavy duty timing belt, RPP5



PGT

Sliding profile, Sliding panel support



PRS50

Stainless steel articulated foot Ø50, Ø 50



GBMz

Cylindrical ballscrew nut, Cylindrical nut - Multiple starts

Complementary products



IN1

Internal gear, Steel 20NC2



ZG1

Plastic spur gear, Machined plastic (delrin)



CLG1

Moulded plastic spur gear, Moulded plastic (nylon)