

Internal gear



MODULE

Steel or **machined** plastic

1.0



- Pressure angle 20°
- Materials:
steel 34C10 or
delrin plastic (machined parts)

Options

- Alternative number of teeth
(minimum 58 teeth)
- Alternative materials (stainless
steel, brass..)

Accessories


- Spur gears with the same module
eg G1.., ZG1..



IN: Steel



ZIN: Plastic

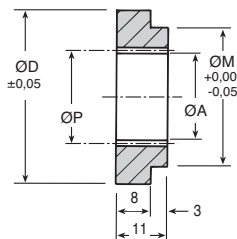

STEEL DISCOUNTS

Qty.	1+	6+	20+	40+
Disc.	List -12%	-25%	On request	

PLASTIC DISCOUNTS

Qty.	1+	6+	30+
Disc.	List -22%	On request	

STEEL IN	PLASTIC ZIN	Z Teeth	PCD ØP	Part number internal ØA	ØD	Boss ØM	Price each 1 to 5	
							STEEL IN	PLASTIC ZIN
IN1-58	ZIN1-58	58	58	56	100	94	60,97 €	43,90 €
IN1-60	ZIN1-60	60	60	58	100	94	61,75 €	44,45 €
IN1-100	ZIN1-100	100	100	98	150	125	105,97 €	76,29 €
Gears available up to this size								
IN1-200	ZIN1-200	200	200	198	250	225	on request	on request

Dimensions in mm

Our other products



PM3

Worm, Non hardened steel



PO

Pull handle - Multi-sector, Tapped recessed insert



T5M T10M

T type timing belt per metre, T5 Steel cored polyurethane



ZDB

Machined plastic bevel gear , 2:1



GLP

Small 6 lobe threaded handle - male, Technopolymer - Stainless steel



BABS303

303 Stainless steel compact ball pin, Stainless steel 303



PRF_ER

Joining bar for aluminium profile, Joint bar



SSB

Stainless steel bevel gear, 1:1



EAR

Bearing locknut, Self locking locknut - nylon



RTE

Rotex®, jaw coupling, steel



ABL100005

Antistatic brush, Standard



HAR9

Captive C washer, DIN 6371

Complementary products



IN1

Internal gear, Steel 20NC2



ZG1

Plastic spur gear, Machined plastic (delrin)



CLG1

Moulded plastic spur gear, Moulded plastic (nylon)