

Internal gear



MODULE

Steel or **machined** plastic

1.0



- Pressure angle 20°
- Materials:
steel 34C10 or
delrin plastic (machined parts)

Options

- Alternative number of teeth
(minimum 58 teeth)
- Alternative materials (stainless
steel, brass..)

Accessories


- Spur gears with the same module
eg G1.., ZG1..



IN: Steel



ZIN: Plastic

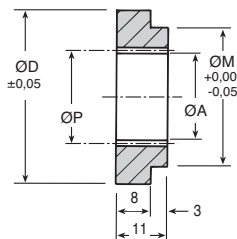

STEEL DISCOUNTS

Qty.	1+	6+	20+	40+
Disc.	List -12%	-25%	On request	

PLASTIC DISCOUNTS

Qty.	1+	6+	30+
Disc.	List -22%	On request	

STEEL IN	PLASTIC ZIN	Z Teeth	PCD ØP	Part number internal ØA	ØD	Boss ØM	Price each 1 to 5	
							STEEL IN	PLASTIC ZIN
IN1-58	ZIN1-58	58	58	56	100	94	60,97 €	43,90 €
IN1-60	ZIN1-60	60	60	58	100	94	61,75 €	44,45 €
IN1-100	ZIN1-100	100	100	98	150	125	105,97 €	76,29 €
Gears available up to this size								
IN1-200	ZIN1-200	200	200	198	250	225	on request	on request

Dimensions in mm

Our other products



SBF
Sealed flange bearing unit for Food Industry, cover



BAN
Angular clamp, Standard



MHQMEP
Arm with rotating handle, Square bore



BTC20_10
End cap for rectangular tube, Standard



EFSM
Igubal® flange bearing, Polymer



PAV
Fixed anti-vibration foot mount, Vibration-dampening




WJUM20
Drylin® W bearing block, Slide



BPQ
Quadro linear ball bearing unit, Included 4 linear ball bearings



 VELM6
Screw-on base for hook-and-loop strip,



RPPM
RPP type belt per metre, RPP14 Steel



VDSQ
Sliding lock adjustment system,



DILC
Indexing plunger with cam, with cam

Complementary products



IN1
Internal gear, Steel
20NC2



ZG1
Plastic spur gear,
Machined plastic
(delrin)



CLG1
Moulded plastic spur gear,
Moulded plastic
(nylon)