

Internal gear



MODULE

Steel or **machined** plastic

1.0



- Pressure angle 20°
- Materials:
steel 34C10 or
delrin plastic (machined parts)

Options

- Alternative number of teeth
(minimum 58 teeth)
- Alternative materials (stainless
steel, brass..)

Accessories


- Spur gears with the same module
eg G1.., ZG1..



IN: Steel



ZIN: Plastic

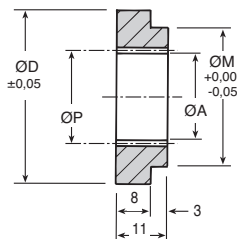

STEEL DISCOUNTS

Qty.	1+	6+	20+	40+
Disc.	List -12%	-25%	On request	

PLASTIC DISCOUNTS

Qty.	1+	6+	30+
Disc.	List -22%	On request	

STEEL IN	PLASTIC ZIN	Z Teeth	PCD ØP	Part number internal ØA	ØD	Boss ØM	Price each 1 to 5	
							STEEL IN	PLASTIC ZIN
IN1-58	ZIN1-58	58	58	56	100	94	60,97 €	43,90 €
IN1-60	ZIN1-60	60	60	58	100	94	61,75 €	44,45 €
IN1-100	ZIN1-100	100	100	98	150	125	105,97 €	76,29 €
Gears available up to this size								
IN1-200	ZIN1-200	200	200	198	250	225	on request	on request


Dimensions in mm

Our other products



PITAss

Locking bolt, with T handle

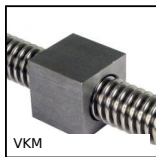

VKM

Square steel nut, Steel - 1 thread



MEP

Revolving handle for handwheel, Fixed



AT5courroie

AT type timing belt, AT5 Steel cored polyurethane



DOMI50

Accessories, Plate



HW_HT

Half-rail guide, Wheel



SCE_SS

Stainless steel U-shaped clamp, Stainless steel



LFM

Steel leadscrew, Medium carbon steel - 1 thread



CHA_GC_9SS

Stainless steel garnet hinge, To be welded



D-PAR_SS

Stainless steel progressive stop,



T10courroie

T type timing belt, T10 Steel cored



ERC

Quick fitting cable terminal, Eye version

Complementary products



IN1

Internal gear, Steel 20NC2



ZG1

Plastic spur gear, Machined plastic (delrin)



CLG1

Moulded plastic spur gear, Moulded plastic (nylon)