

Internal gear



MODULE

Steel or **machined** plastic

1.0



- Pressure angle 20°
- Materials:
steel 34C10 or
delrin plastic (machined parts)

Options

- Alternative number of teeth
(minimum 58 teeth)
- Alternative materials (stainless
steel, brass..)

Accessories


- Spur gears with the same module
eg G1.., ZG1..



IN: Steel



ZIN: Plastic

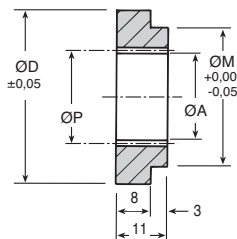

STEEL DISCOUNTS

Qty.	1+	6+	20+	40+
Disc.	List -12%	-25%	On request	

PLASTIC DISCOUNTS

Qty.	1+	6+	30+
Disc.	List -22%	On request	

STEEL IN	PLASTIC ZIN	Z Teeth	PCD ØP	Part number internal ØA	ØD	Boss ØM	Price each 1 to 5	
							STEEL IN	PLASTIC ZIN
IN1-58	ZIN1-58	58	58	56	100	94	60,97 €	43,90 €
IN1-60	ZIN1-60	60	60	58	100	94	61,75 €	44,45 €
IN1-100	ZIN1-100	100	100	98	150	125	105,97 €	76,29 €
Gears available up to this size								
IN1-200	ZIN1-200	200	200	198	250	225	on request	on request

Dimensions in mm

Our other products



PTA150
Articulated levelling
foot, pressed base
Ø150, 40000N



NK17
Drylin®N miniature
guiding system, Width
17 mm



CLG1
Moulded plastic spur
gear, Moulded plastic
(nylon)



PRF-GPA
Guide for aluminium
profile, Parallel rails



CHA_GC_145S
Stainless steel garnet
hinge, To screw



PPF
Indexing plunger with
flange, with drilled
flange



SBF
Sealed flange bearing
unit for Food Industry,
cover



GAL48_OMNI
Omni-directional
roller, Omni-
directional



PTA100
Articulated levelling
foot, pressed base



VTHbr
Hexagonal headed
screw VTH - DIN933,



BPHT
Ball transfer unit bolt
fitting, Heavy



PSPT
Flexible tube handle,
PVC

Complementary products



IN1
Internal gear, Steel
20NCD2



ZG1
Plastic spur gear,
Machined plastic
(delrin)



CLG1
Moulded plastic spur
gear, Moulded plastic
(nylon)