

Steel or **machined** plastic

MODULE  
**2.0**



- Pressure angle 20°
- Materials:  
steel 34C10 or  
delrin plastic (machined parts)

### Options

- Alternative number of teeth
- Alternative materials (stainless steel, brass..)

### Accessories

- Spur gears with the same module eg G2.., ZG2..




IN: Steel



ZIN: Plastic

**NEW!**

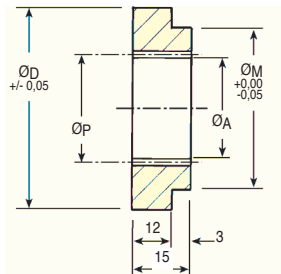

### STEEL DISCOUNTS

Qty.	1+	6+	20+	40+
Disc.	List -12%	-25%	On request	

### PLASTIC DISCOUNTS

Qty.	1+	6+	30+
Disc.	List -22%	On request	

STEEL IN	PLASTIC ZIN	Z Teeth	PCD ØP	Part number Internal ØA	ØD	Boss ØM	Price each 1 to 5	STEEL IN	PLASTIC ZIN
IN2-40	ZIN2-40	40	80	76	150	125	96,05 €	67,23 €	
IN2-60	ZIN2-60	60	120	116	175	150	149,65 €	104,75 €	
IN2-80	ZIN2-80	80	160	156	220	200	196,94 €	137,86 €	
IN2-100	ZIN2-100	100	200	196	250	220	253,33 €	177,33 €	
<b>Gears available up to this size</b>									
IN2-110	ZIN2-110	110	220	216	280	250	295,14 €	206,60 €	

Dimensions in mm

## Our other products



PO  
Pull handle - Multi-sector, Tapped recessed insert



PSG08  
Spur gear - precision range, Pre-hardened Steel 35NCD6



DOM120  
Accessories, Clamping lever



PTA80  
Articulated levelling foot, pressed base Ø80, Ø 80



BSM\_LOK  
Long-Lok spring plunger with internal hexagonal socket, LONG-LOK - s...



PLM-C  
Cylindrical holding magnets, Cylindrical holding magnet



PCS50K  
Chain sprocket with hardened teeth, 12.7mm (DIN08B-1)



TAC\_SS  
Stainless steel rigging screw (hook/eye), Stainless steel




PW\_PWG15  
Wheel - precision range, Bronze



PSG25  
Spur gear - precision range, Pre-hardened




 CQA30  
Adjustment slide-system miniature, 30



PO  
Pull handle - Multi-sector, Smooth hole

## Complementary products

 

IN2  
Internal gear, Machined plastic (delrin)



G2  
Steel spur gear, Steel 20NCD2



GG2  
Ground spur gear, Heat treated steel