

Steel or **machined** plastic

MODULE
2.0



- Pressure angle 20°
- Materials:
steel 34C10 or
delrin plastic (machined parts)

Options

- Alternative number of teeth
- Alternative materials (stainless steel, brass..)

Accessories

- Spur gears with the same module eg G2.., ZG2..




IN: Steel



ZIN: Plastic

NEW!

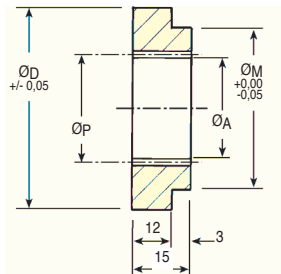

STEEL DISCOUNTS

Qty.	1+	6+	20+	40+
Disc.	List -12%	-25%	On request	

PLASTIC DISCOUNTS

Qty.	1+	6+	30+
Disc.	List -22%	On request	

STEEL IN	PLASTIC ZIN	Z Teeth	PCD Part number Internal		Boss ØM	Price each 1 to 5	
			ØP	ØA		STEEL IN	PLASTIC ZIN
IN2-40	ZIN2-40	40	80	76	150	125	96,05 € 67,23 €
IN2-60	ZIN2-60	60	120	116	175	150	149,65 € 104,75 €
IN2-80	ZIN2-80	80	160	156	220	200	196,94 € 137,86 €
IN2-100	ZIN2-100	100	200	196	250	220	253,33 € 177,33 €
Gears available up to this size							
IN2-110	ZIN2-110	110	220	216	280	250	295,14 € 206,60 €

Dimensions in mm

Our other products



Spherical bushing,
Steel / steel



Conical flexible shaft
handle Ø20, Black
PVC



Sealing strip, Clipping



Machined plastic
bevel gear , 2:1



Spur gear - precision
range, Stainless steel
316



Indexing plunger,
steel class 5.8



 
Horizontal hook
toggle clamp,
Horizontal Hook
clamp - steel



Hinge for aluminium
profile, Hinge




Slip friction clutch, 4
to 2600 Nm



Crossed helical gear
crossed axis at 90°



 Nylon tipped set
screw, Nylon-point



Right angled gearbox,
up to 128 Nm

Complementary products



Internal gear, Steel
20NC2



Plastic spur gear,
Machined plastic
(delrin)



Moulded plastic spur
gear, Moulded plastic
(nylon)