

# Self tapping inserts- coarse thread

## INS100

### For soft materials


- Self tapping insert with coarse external thread
- No collar
- Deforms on installation, no special tools required
- Hexagonal drive socket simplifies installation
- Chromed steel

### Applications

- For use in rubber, soft plastic or soft wood

### Info.

- Sold by the packet

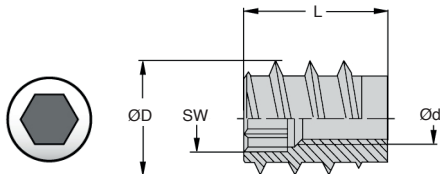

### DISCOUNTS

Qty	1+	10+	20+	30+	40+
Disc.	List	-5%	-10%	-15%	On request

Part number	ØD	L	Ød	SW	Recommended Ø drill		Packet qty	Weight (g)	Stock*	Price each by packet
					min	max				
INS100-M4/B	8,0	8	M4	4	6,6	6,9	20	1,4	✓	10,27 €
INS100-M5/B	10,0	10	M5	5	8,4	8,9	20	2,5	✓	13,06 €
INS100-M6/B	12,0	12	M6	6	10,0	10,4	20	4,8	✓	16,25 €
INS100-M8/B	14,0	15	M8	8	12,0	12,4	20	7,3	✓	27,27 €
INS100-M10/B	18,5	20	M10	10	16,2	16,7	15	19,2	✓	42,60 €
INS100-M12/B	22,0	30	M12	12	19,5	20,0	10	38,0	-	127,30 €

\*Depending on availability - Dimensions in mm

 
HPC

WEB  
04/2020

www.hpceurope.com

Tél: 0 825 88 5000 Service 0,15 €/min + prix appel

## Our other products



PRZ

Wear strip for slat top chain, Z profile to be filled



PRF\_PF

Anchoring bracket for aluminium profile, Anchor



SRG

Adjustable latch clamp with strike plate, Stroke from 96mm to 121,7mm



MC

Self-compensating shock-absorber, Self-compensating - without adjust...



CDC

Conical compression spring, Conical




BABss

303 Stainless steel ball pin, 303 Stainless steel



PGM52-M4

 Pull handle, Brass



RDE-W

Sealing washer Hygienic Usit®, Stainless steel - White EPDM



FDS

Flexible drive shaft, Masterflex® Steel,



F7-E

Multifunction display, With external sensor



ZBconigue

Machined plastic bevel gear, 1:1



HW\_HT

Half-rail guide, Wheel

## Complementary products



INS150

Self tapping insert with collar-coarse thread, With collar-coarse t...



INS

Self tapping steel insert, Steel



BOX-INS-W

Box set of self tapping inserts, Boxed set - For wood



INStool

Insertion tool for self tapping inserts, Insertion tool