

Self tapping insert with collar-coarse thread

For soft materials

INS150

- Self tapping insert with coarse external thread
- With collar
- Deforms on installation, no special tools required
- Hexagonal drive socket simplifies installation
- Chromed steel

Applications

- For use in rubber, soft plastic or soft wood


Advantage

- Collar prevents insert being inserted too far

Info.

- Sold by the packet

With collar

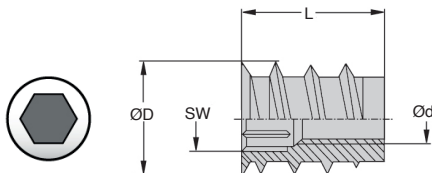

DISCOUNTS

| Qty | 1+ | 10+ | 20+ | 30+ | 40+ |
|-------|------|-----|------|------|------------|
| Disc. | List | -5% | -10% | -15% | On request |

| Part number | ØD | L | Ød | SW | Recommended Ø drill | | Packet qty | Weight (g) | Stock* | Price each by packet |
|--------------|------|----|-----|----|---------------------|------|------------|------------|--------|----------------------|
| | | | | | min | max | | | | |
| INS150-M4/B | 8,0 | 8 | M4 | 4 | 6,6 | 6,9 | 20 | 1,4 | ✓ | 29,28 € |
| INS150-M5/B | 10,0 | 12 | M5 | 5 | 8,4 | 8,9 | 20 | 2,8 | ✓ | 36,42 € |
| INS150-M6/B | 12,0 | 15 | M6 | 6 | 10,0 | 10,4 | 20 | 6,0 | ✓ | 42,90 € |
| INS150-M8/B | 14,0 | 18 | M8 | 8 | 12,0 | 12,4 | 20 | 8,7 | ✓ | 71,53 € |
| INS150-M10/B | 18,5 | 25 | M10 | 10 | 16,2 | 16,7 | 15 | 24,2 | ✓ | 83,54 € |
| INS150-M12/B | 22,0 | 25 | M12 | 12 | 19,5 | 20,0 | 10 | 34,5 | - | 100,78 € |

*Depending on availability - Dimensions in mm

Our other products



PDR-RD

Mounting feet with integrated castors, Offset castor



MC

Self-compensating shock-absorber, Self-compensating - without adjust...



TMR

Rigid manual tensioner, Adjustable



SVTS

Screwjack with travelling screw, with translating screw



TK_UUOP

Topball self-aligning linear bearing, Topball self-aligning



PW_PWG15

Wheel - precision range, Bronze



RTN

BoWex® curved tooth gear coupling, Nylon



CHM90

Worm and wheel gear reducer, up to 540 Nm



PFM

Fixed levelling foot, Flanged plate



MEP

Revolving handle for handwheel, Fixed



CHTRB

Single and dual output gearboxes, Up to 53,1 Nm



AT5courroie

AT type timing belt, AT5 Steel cored polyurethane

Complementary products



INS100

Self tapping inserts-coarse thread, Coarse thread



BOX-INS-W

Box set of self tapping inserts, Boxed set - For wood



INSTool

Insertion tool for self tapping inserts, Insertion tool



CHC

Socket headed screw, Steel class 12.19