

# Self tapping insert with collar-coarse thread

For soft materials

INS150

- Self tapping insert with coarse external thread
- With collar
- Deforms on installation, no special tools required
- Hexagonal drive socket simplifies installation
- Chromed steel

## Applications

- For use in rubber, soft plastic or soft wood


## Advantage

- Collar prevents insert being inserted too far

## Info.

- Sold by the packet

With collar

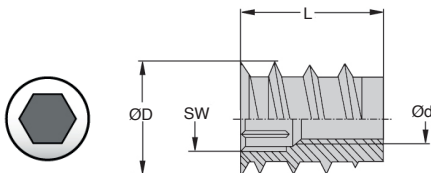

## DISCOUNTS

Qty	1+	10+	20+	30+	40+
Disc.	List	-5%	-10%	-15%	On request

Part number	ØD	L	Ød	SW	Recommended Ø drill		Packet qty	Weight (g)	Stock*	Price each by packet
					min	max				
INS150-M4/B	8,0	8	M4	4	6,6	6,9	20	1,4	✓	29,28 €
INS150-M5/B	10,0	12	M5	5	8,4	8,9	20	2,8	✓	36,42 €
INS150-M6/B	12,0	15	M6	6	10,0	10,4	20	6,0	✓	42,90 €
INS150-M8/B	14,0	18	M8	8	12,0	12,4	20	8,7	✓	71,53 €
INS150-M10/B	18,5	25	M10	10	16,2	16,7	15	24,2	✓	83,54 €
INS150-M12/B	22,0	25	M12	12	19,5	20,0	10	34,5	-	100,78 €

\*Depending on availability - Dimensions in mm

## Our other products



GP

Spring loaded toggle latch, With padlock-holder



PDM\_PDV

Detectable plastic palm grip, by metal detectors



UCF

Cast iron flange bearing unit, Cast iron



SCR

Suction cup threaded insert, Insert for suction cup - Socket screw



VPR

Wing screw Hygienic Usit®, Stainless steel



DIA

Ring operated locking bolt, with ring



CNA-CNG

Right angled mounting plate, Right angled mounting plate for clevis



MDR\_SS

Stainless steel Dee shackle with eye bolt, Stainless steel




PTA50

Articulated levelling foot, pressed base



BWU

 Compact precision slide, from 1510 N to



BCM\_CC

Modular cylindrical brush, Horsehair



GAC

Lock for latch clamp, Strike plate

## Complementary products



INS100

Self tapping inserts-coarse thread, Coarse thread



BOX-INS-W

Box set of self tapping inserts, Boxed set - For wood



INSTool

Insertion tool for self tapping inserts, Insertion tool



CHC

Socket headed screw, Steel class 12.19