 


Insertion tool for self tapping inserts

Assembly tool

INSTOOL

- Insertion tool for self tapping inserts
- Hexagonal shaft and rotating hexagonal end



Example of a typical application

DISCOUNTS

| Qty | 1+ | 10+ | 20+ | 30+ | 40+ |
|-------|------|-----|------|------|------------|
| Disc. | List | -5% | -10% | -15% | On request |

| Part number | Ød | SW | Stock* | Price each 1 to 9 |
|-----------------|-----|----|--------|----------------------|
| INS300-TOOL-M3 | M3 | 10 | ✓ | 89,30 € |
| INS300-TOOL-M4 | M4 | 10 | ✓ | 89,30 € |
| INS300-TOOL-M5 | M5 | 17 | ✓ | 101,20 € |
| INS300-TOOL-M6 | M6 | 17 | ✓ | 101,20 € |
| INS300-TOOL-M8 | M8 | 17 | ✓ | 116,11 € |
| INS300-TOOL-M10 | M10 | 19 | ✓ | 122,06 € |
| INS300-TOOL-M12 | M12 | 19 | ✓ | 157,79 € |

*Depending on availability - Dimensions in mm

Fax: 0 825 88 6000 > Service 0,15€/mln + prix appel

cial2@hpceurope.com

WEB
04/2020

HPC

Our other products



 
M1

Worm, Hardened steel



PRF_PA

Connecting/joining,
Adjustable plate



JFM

Bushing, Universal
polymer



CM_CO

Tools Hygienic Usit®
and Hygienic
Design®, Protective
inserts for open-



NSR

Adjustable cross
clamp, Adjustable



GE_ET_2RS

Spherical bearing,
Hard chromium /
Teflon contact with
seals



PLB

Spacer, Brass



EKGS

Backlash free
coupling Gerwah®,
from 0.5 to 35Nm



RAM30

Manual gearbox,
Bevel




CHAu

Front hinge, 270°



PSG05S

Spur gear - precision
range, Stainless steel
303

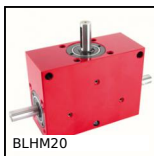

BLHM20

Right angled gearbox,
up to 1.77 Nm

Complementary products



INS

Self tapping insert,
Steel



INS_BR

Self tapping insert,
Brass



INS_SS

Self tapping insert,
Stainless steel



INS100

Self tapping insert,
Coarse thread