


Spur gear coaxial gearbox

Technical information

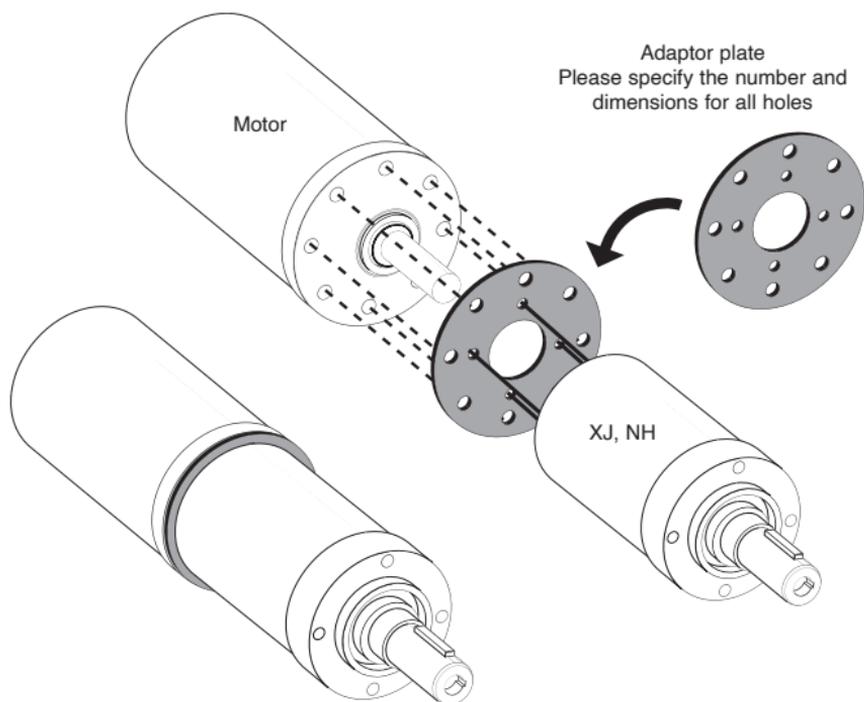

Input face of the XJ reducers



Output face of the XJ reducers




XJ + NH Reducers:

Please supply us with the dimensions of the face plate of your motor

Torque up to 0.49Nm

J51
XJ51


- Ratios from 1:1 to 20:1
(Other ratios available on request)
- Output backlash: 3-6° depending on ratio
- Max. input speed: 4,000 rpm
- Materials:
casing: anodised aluminium and black Delrin
input & output: non-hardened steel
- Weight: 0.14 kg
- Keyway conforms to DIN 6885

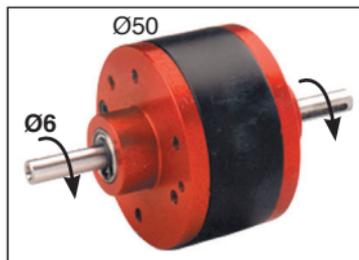

XJ Gearbox

- Please send us the dimensions of the front face of your motor
- The overall length depends on the adaptor plate

(2x3) M4 x 5mm
deep on 38mm PCD

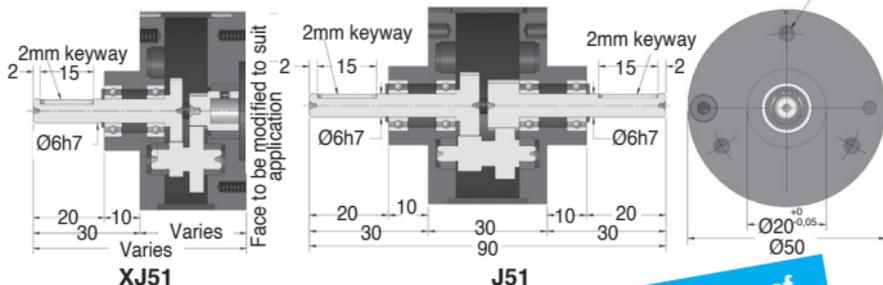

OUTPUT TORQUE (In Nm, values given as a guide only)

Ratios	2:1	3:1	4:1	5:1	10:1	15:1	20:1
4000	0,16	0,15	0,14	0,13	0,15	0,17	0,18
2000	0,19	0,18	0,17	0,15	0,18	0,20	0,21
1000	0,22	0,22	0,20	0,18	0,21	0,22	0,23
500	0,27	0,25	0,23	0,21	0,24	0,25	0,27
200	0,32	0,30	0,27	0,25	0,28	0,30	0,32
100	0,36	0,33	0,30	0,28	0,32	0,34	0,36
50	0,40	0,38	0,35	0,32	0,36	0,37	0,42
20	0,48	0,45	0,41	0,38	0,43	0,44	0,49

Large choice of
reduction ratios!
Up to 625:1

IN STOCK*
Otherwise contact us

DISCOUNTS

Qty	1+	2+	4+	6+
Disc.	List	-15%	-20%	On request

Part number	Ratios	Max. input speed (rpm)	Max. output speed (rpm)	Efficiency at 1000 rpm	Direction of input/output rotation	Price each J	Price each XJ
J51-2	XJ51-2	2:1	4000	2000	92%	Same	511,89 €
J51-3	XJ51-3	3:1	4000	1333	92%	Same	511,89 €
J51-4	XJ51-4	4:1	4000	1000	92%	Same	511,89 €
J51-5	XJ51-5	5:1	4000	800	92%	Same	511,89 €
J51-10	XJ51-10	10:1	4000	400	92%	Same	511,92 €
J51-15	XJ51-15	15:1	4000	266	92%	Same	511,92 €
J51-20	XJ51-20	20:1	4000	200	92%	Same	511,92 €
J51-SP	XJ51-SP	1:1 - 20:1	Special ratios from 1:1 to 20:1				719,54 €

*Depending on availability - Dimensions in mm


Spur gear coaxial gearbox



J52 XJ52


Torque up to 0.9Nm

- Ratios from 1:1 to 130:1
(Other ratios available on request)
- Output backlash: 3-6° depending on ratio
- Max. input speed: 4,000 rpm
- Materials:
casing: anodised aluminium
and black Delrin
input & output: non-hardened steel
- Weight: 0.16 kg
- Keyway conforms to DIN 6885

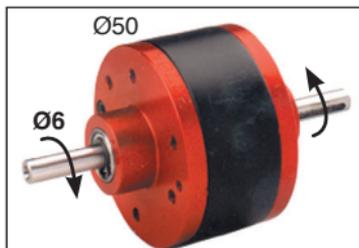

XJ Gearbox

- Please send us the dimensions of the front face of your motor
- The overall length depends on the adaptor plate

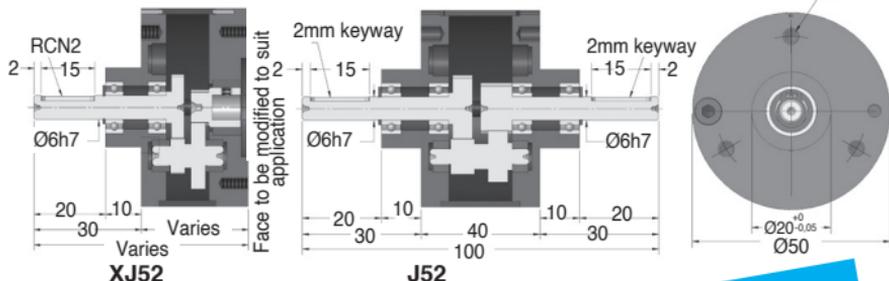

OUTPUT TORQUE (In Nm, values given as a guide only)

Ratios	30:1	40:1	50:1	60:1	75:1	100:1	125:1
4000	0,27	0,28	0,29	0,30	0,31	0,33	0,34
2000	0,30	0,32	0,33	0,34	0,35	0,38	0,40
1000	0,34	0,36	0,38	0,40	0,41	0,42	0,43
INPUT SPEED (rpm)	500	0,40	0,41	0,42	0,43	0,46	0,49
200	0,46	0,48	0,49	0,52	0,54	0,57	0,59
100	0,52	0,55	0,57	0,59	0,61	0,65	0,69
50	0,57	0,62	0,65	0,69	0,73	0,74	0,75
20	0,69	0,73	0,75	0,75	0,75	0,90	0,90

Large choice of reduction ratios!
Up to 625:1

DISCOUNTS

Qty	1+	2+	4+	6+
Disc.	List	-15%	-20%	On request

Part number	Ratios	Max. input speed (rpm)	Max. output speed (rpm)	Efficiency at 1000 rpm	Direction of input/output rotation	Price each J	XJ
J52-30	XJ52-30	30:1	4000	133	88%	Opposite	707,02 €
J52-40	XJ52-40	40:1	4000	100	88%	Opposite	707,02 €
J52-50	XJ52-50	50:1	4000	80	88%	Opposite	707,02 €
J52-60	XJ52-60	60:1	4000	66	88%	Opposite	707,02 €
J52-75	XJ52-75	75:1	4000	53	88%	Opposite	707,02 €
J52-100	XJ52-100	100:1	4000	40	88%	Opposite	707,02 €
J52-125	XJ52-125	125:1	4000	32	88%	Opposite	707,02 €
J52-SP	XJ52-SP	1:1 - 130:1	Special ratios from 1:1 to 130:1				833,18 €

On request

Dimensions in mm

Torque up to 1.15Nm

J53
XJ53

- Ratios from 1:1 to 625:1
(Other ratios available on request)

- Output backlash: N/A

- Max. input speed: 4,000 rpm


- Materials:

casing: anodised aluminium
and black Delrin

input & output: non-hardened steel

- Weight: 0.17 kg


- Keyway conforms to DIN 6885

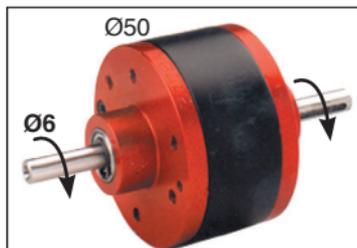

XJ Gearbox

- Please send us the dimensions of the front face of your motor

- The overall length depends on the adaptor plate

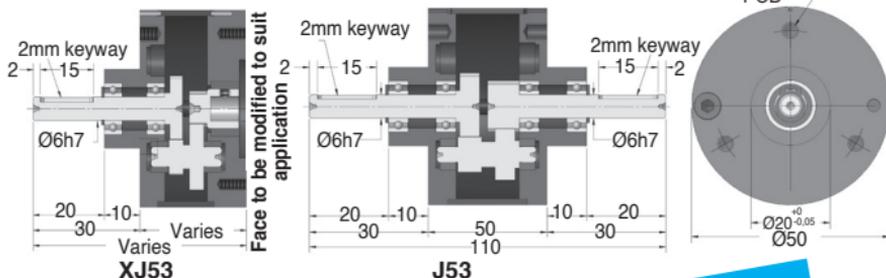

OUTPUT TORQUE (In Nm, values given as a guide only)

Ratios	140:1	160:1	200:1	300:1	400:1	500:1	625:1
4000	0,43	0,45	0,46	0,51	0,53	0,55	0,58
2000	0,50	0,52	0,53	0,58	0,59	0,61	0,63
1000	0,56	0,57	0,58	0,63	0,65	0,67	0,69
INPUT SPEED (rpm)	500	0,63	0,67	0,69	0,69	0,79	0,84
	200	0,76	0,79	0,79	0,79	0,91	0,99
	100	0,86	0,91	0,91	0,91	1,15	1,15
	50	0,95	0,95	0,95	0,95	1,15	1,15
	20	1,15	1,15	1,15	1,15	1,15	1,15

Large choice of reduction ratios!
Up to 625:1

DISCOUNTS

Qty	1+	2+	4+	6+
Disc.	List	-15%	-20%	On request

Part number	Ratios	Max. input speed (rpm)	Max. output speed (rpm)	Efficiency at 1000 rpm	Direction of input/output rotation	Price each J	XJ
J53-140	XJ53-140	140:1	4000	29	85%	Same	945,17 €
J53-160	XJ53-160	160:1	4000	25	85%	Same	945,17 €
J53-200	XJ53-200	200:1	4000	20	85%	Same	945,17 €
J53-300	XJ53-300	300:1	4000	13	85%	Same	945,17 €
J53-400	XJ53-400	400:1	4000	10	85%	Same	945,17 €
J53-500	XJ53-500	500:1	4000	8	85%	Same	945,17 €
J53-625	XJ53-625	625:1	4000	6,40	85%	Same	945,17 €
J53-SP	XJ53-SP	1:1 - 625:1	Special ratios from 1:1 to 625:1				1 080,42 €

Dimensions in mm


Spur gear coaxial gearbox



J64 XJ64


Torque up to 2.25Nm

- Ratios from 1:1 to 16:1
(Other ratios available on request)
- Output backlash: N/A
- Max. input speed: 4,000 rpm
- Materials:
casing: anodised aluminium
and black Delrin
input & output: non-hardened steel
- Weight: 0.3 kg
- Keyway conforms to DIN 6885

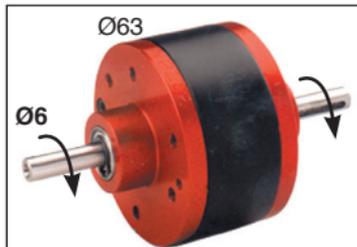

XJ Gearbox

- Please send us the dimensions of the front face of your motor
- The overall length depends on the adaptor plate

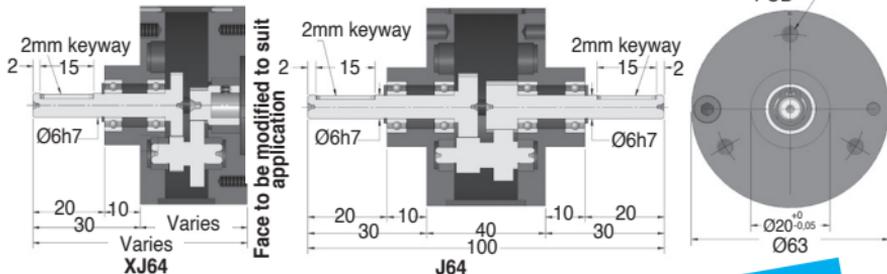

OUTPUT TORQUE (In Nm, values given as a guide only)

Ratios	2:1	3:1	4:1	6:1	10:1	12:1	16:1
4000	0,66	0,64	0,57	0,75	0,70	0,79	0,80
2000	0,84	0,81	0,72	0,88	0,81	0,90	0,92
1000	0,99	0,96	0,85	1,00	0,90	1,04	1,07
INPUT SPEED (rpm)	500	1,13	1,10	0,98	1,14	1,01	1,17
	200	1,32	1,28	1,14	1,35	1,20	1,39
	100	1,50	1,45	1,30	1,53	1,33	1,58
	50	1,68	1,63	1,46	1,68	1,53	1,81
	20	2,00	1,95	1,74	2,00	1,80	2,10

**Large choice of reduction ratios!
Up to 256:1**

DISCOUNTS

Qty	1+	2+	4+	6+
Disc. List	-15%	-20%	-20%	On request

Part number	Ratios	Max. input speed (rpm)	Max. output speed (rpm)	Efficiency at 1000 rpm	Direction of input/output rotation	Price each J	XJ
J64-2	XJ64-2	2:1	4000	2000	92%	Same	670,32 €
J64-3	XJ64-3	3:1	4000	1333	92%	Same	670,32 €
J64-4	XJ64-4	4:1	4000	1000	92%	Same	670,32 €
J64-6	XJ64-6	6:1	4000	666	92%	Same	670,32 €
J64-10	XJ64-10	10:1	4000	400	92%	Same	670,32 €
J64-12	XJ64-12	12:1	4000	333	92%	Same	670,32 €
J64-16	XJ64-16	16:1	4000	250	92%	Same	670,32 €
J64-SP	XJ64-SP	1:1 - 16:1	Special ratios from 1:1 to 16:1			820,13 €	

On request

Dimensions in mm




Spur gear coaxial gearbox

Torque up to 2.95Nm

J65
XJ65


- Ratios from 1:1 to 64:1
(Other ratios available on request)
- Output backlash: N/A
- Max. input speed: 4,000 rpm
- Materials:
 - casing: anodised aluminium and black Delrin
 - input & output: non-hardened steel
- Weight: 0.32 kg
- Keyway conforms to DIN 6885

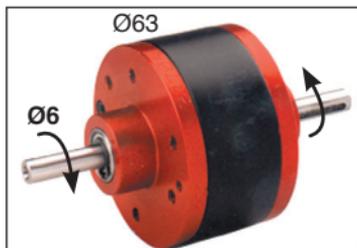


XJ Gearbox

- Please send us the dimensions of the front face of your motor
- The overall length depends on the adaptor plate


(2x3) M4 x 5mm
deep on 38mm PCD

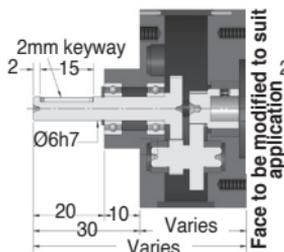

XJ65

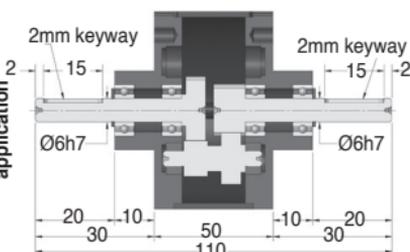

J65

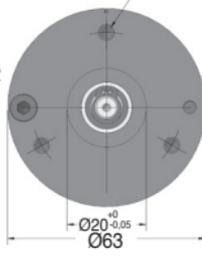

OUTPUT TORQUE (In Nm, values given as a guide only)

Ratios	15:1	20:1	24:1	32:1	40:1	48:1	64:1
4000	0,80	0,81	0,91	0,92	0,89	0,91	0,92
2000	0,91	0,93	1,04	1,05	1,03	1,04	1,06
1000	1,05	1,10	1,16	1,20	1,16	1,19	1,23
500	1,20	1,27	1,35	1,41	1,37	1,40	1,45
200	1,40	1,63	1,58	1,63	1,56	1,61	1,63
100	1,48	1,71	1,80	1,85	1,73	1,82	1,87
50	1,86	2,02	1,95	2,00	1,94	1,95	1,96
20	2,20	2,30	2,36	2,45	2,36	2,40	2,95

Large choice
of reduction
ratios!
Up to 256:1

DISCOUNTS

Qty	1+	2+	4+	6+
Disc.	List	-15%	-20%	On request

Part number	Ratios	Max. input speed (rpm)	Max. output speed (rpm)	Efficiency at 1000 rpm	Direction of input/output rotation	Price each J	XJ
J65-15	XJ65-15	15:1	4000	266	88%	Opposite	796,65 €
J65-20	XJ65-20	20:1	4000	200	88%	Opposite	796,65 €
J65-24	XJ65-24	24:1	4000	166	88%	Opposite	796,65 €
J65-32	XJ65-32	32:1	4000	125	88%	Opposite	796,65 €
J65-40	XJ65-40	40:1	4000	100	88%	Opposite	796,65 €
J65-48	XJ65-48	48:1	4000	83	88%	Opposite	796,65 €
J65-64	XJ65-64	64:1	4000	62	88%	Opposite	796,65 €
J65-SP	XJ65-SP	1:1 - 64:1	Special ratios from 1:1 to 64:1				937,26 €

Dimensions in mm

On request


Spur gear coaxial gearbox



J66 XJ66


Torque up to 2.8Nm

- Ratios from 1:1 to 256:1
(Other ratios available on request)
- Output backlash: N/A
- Max. input speed: 4,000 rpm
- Materials:
casing: anodised aluminium
and black Delrin
input & output: non-hardened steel
- Weight: 0.34 kg
- Keyway conforms to DIN 6885

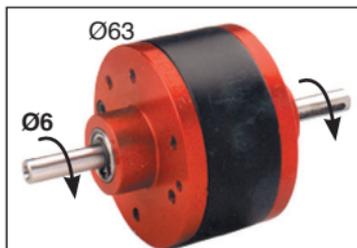

XJ Gearbox

- Please send us the dimensions of the front face of your motor
- The overall length depends on the adaptor plate

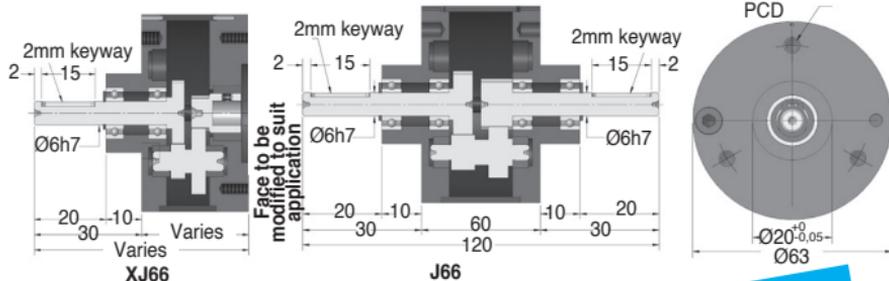

OUTPUT TORQUE (In Nm, values given as a guide only)

	Ratios	50:1	80:1	96:1	128:1	160:1	192:1	256:1
INPUT SPEED (rpm)	4000	0,90	1,01	1,05	1,09	1,13	1,25	1,40
	2000	1,04	1,13	1,18	1,24	1,30	1,40	1,55
	1000	1,18	1,30	1,33	1,39	1,44	1,60	1,85
	500	1,40	1,44	1,50	1,58	1,64	1,78	2,00
SPEED (rpm)	200	1,60	1,73	1,80	1,87	1,96	2,18	2,42
	100	1,82	1,96	2,10	2,17	2,28	2,47	2,80
	50	2,02	2,28	2,45	2,61	2,80	2,80	2,80
	20	2,50	2,80	2,80	2,80	2,80	2,80	2,80

**Large choice of reduction ratios!
Up to 256:1**

DISCOUNTS

Qty	1+	2+	4+	6+
Disc.	List -15%	-20%	On request	On request

Part number	Ratios	Max. input speed (rpm)	Max. output speed (rpm)	Efficiency at 1000 rpm	Direction of input/output rotation	Price each J	XJ
J66-50	XJ66-50	50:1	4000	80	85%	Same	944,46 €
J66-80	XJ66-80	80:1	4000	50	85%	Same	944,46 €
J66-96	XJ66-96	96:1	4000	41	85%	Same	944,46 €
J66-128	XJ66-128	128:1	4000	31	85%	Same	944,46 €
J66-160	XJ66-160	160:1	4000	25	85%	Same	944,46 €
J66-192	XJ66-192	192:1	4000	21	85%	Same	944,46 €
J66-256	XJ66-256	256:1	4000	15	85%	Same	944,46 €
J66-SP	XJ66-SP	1:1 - 256:1	Special ratios from 1:1 to 256:1				1 087,36 €

Dimensions in mm

On request