

- **Stainless steel range**
- **Plain pins and bushes**
- Suitable for speeds up to 800 rpm
- Max. angle of misalignment 90°
- Material:  
Stainless steel X5CrNi1810




### Uses

- Food and pharmaceutical industries

### Accessories

- Optional rubber cover

### modifiable bore-size

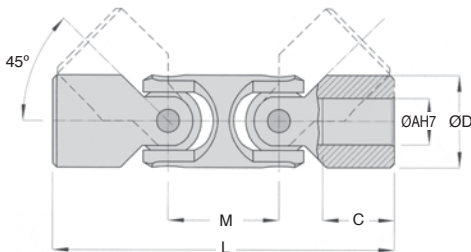

### Angle Factor

Angle	Factor
5°	1,25
10°	1,00
20°	0,75
30°	0,45
40°	0,30

### Effect of operating angle

The torques below are given for a 10° angle. For other angles, the appropriate factor from this table should be applied. E.g. For 10Nm to be transmitted at 20°, the corrected value of torque becomes  $10/0.75 = 13.3$  Nm and a joint should be chosen that can transmit 13.3Nm at the required speed.

### DISCOUNTS

Qty.	1+	5+	10+	25+	50+
Disc.	List	-6%	-12%	-18%	On request

Part number	ØD	ØA	C	M	L	Torque (Nm)								Price each 1 to 4
						at 100 rpm	at 200 rpm	at 300 rpm	at 400 rpm	at 500 rpm	at 700 rpm	at 800 rpm	Stock*	
JCD04/SS	22	12	25	29	105	18,9	11,34	9,00	7,20	6,57	5,67	5,22	✓	88,68 €
JCD05/SS	25	14	29	33	119	29,7	19,17	17,37	15,84	14,67	11,97	11,34	-	92,25 €
JCD06/SS	29	16	30	35	125	40,5	37,80	31,77	25,20	22,77	18,00	15,57	✓	95,76 €
JCD07/SS	32	18	30	39	134	68,4	54,00	41,94	31,77	26,37	20,97	-	-	113,51 €
JCD08/SS	40	20	32	46	154	105,3	75,60	52,74	41,94	37,17	26,37	-	✓	124,15 €
JCD09/SS	40	22	38	46	173	131,4	86,40	63,00	52,74	41,94	31,77	-	-	156,11 €
JCD10/SS	50	25	44	59	199	172,8	108,00	75,60	64,80	54,00	43,20	-	-	184,53 €
JCD11/SS	58	30	58	66	244	194,4	118,80	86,40	70,20	59,40	-	-	-	241,30 €

\*Depending on availability - Dimensions in mm

## Our other products



ERC  
Quick fitting cable terminals, Fork



CHAR16046  
Spring hinges, screwed



WTM  
Tightening washer - DIN 6340, Steel



FRTC\_FRNC  
Rotary dampener, 2 and 3Ncm




PENV  
Recessed handle, screw fixing



ARL\_SRS  
Plastic flexible rack, Rack clamp



B332  
Right angled gearbox, miniature

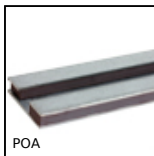

POA  
Magnetic workshop tool support, Magnetic bar



BG  
Oldham, With set screw



PFM  
Pressed steel foot, Flanged plate



PRFRTR  
Connecting/joining, Cross connector



DOMI120  
DOMILINE - Accessories, Clamping lever

## Complementary products



M  
Bellows cover, Standard



H02SS  
Universal joint - stainless steel, Needle bearings - single



HDSS  
Universal joint - stainless steel, Needle bearings - double