




Flanged polymer bush

The speed specialist

JFM

- **Material:** iglidur® J
- Yellow
- **Working temperature:** -50°C to +90°C
(+60°C ideal, +120°C for short periods)
- **Max. continuous speed:**
Rotating 1.5 m/s
Oscillating 1.5 m/s
Linear 8 m/s
- **Pressure resistance:**
at +20°C 35 N/mm² (ideally 2 N/mm²)
- **Friction coefficient**
dry 0.06-0.18
greased 0.09
water/oil 0.04
- **Not sold individually, please contact us for details**

Maintenance free

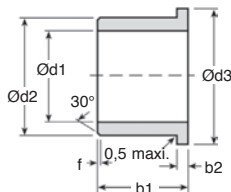

Assembly

- Recommended assembly tolerances shaft h9, housing bore-size H7
- Shaft treated 50 HRC, surface finish 0.8-2 µm

Options

- Bore diameter up to 70mm

DISCOUNTS

Qty	1+	10+	25+	50+	100+	200+	500+
Disc.	List	-10%	-25%	-40%	-50%	-60%	On request


Part number	Ød1	Ød2	Ød3 (d13)	b1 (h13)	b2 (-0,14)	f	Stock*	Price each 1 to 9
JFM0304-05	3 ^{+0,014 +0,054}	4,5	7,5	5	0,75	0,5	✓	2,60 €
JFM0405-06	4 ^{+0,020 +0,068}	5,5	9,5	6	0,75	0,5	✓	2,60 €
JFM0507-05	5 ^{+0,020 +0,068}	7,0	11,0	5	1,00	0,5	✓	2,60 €
JFM0608-06	6 ^{+0,020 +0,068}	8,0	12,0	6	1,00	0,5	✓	2,76 €
JFM0608-10	6 ^{+0,020 +0,068}	8,0	12,0	10	1,00	0,5	✓	2,89 €
JFM0810-06	8 ^{+0,025 +0,083}	10,0	15,0	6	1,00	0,5	✓	3,12 €
JFM0810-08	8 ^{+0,025 +0,083}	10,0	15,0	8	1,00	0,5	✓	3,24 €
JFM0812-06	8 ^{+0,025 +0,083}	12,0	16,0	6	1,00	0,5	✓	4,23 €
JFM1012-05	10 ^{+0,025 +0,083}	12,0	18,0	5	1,00	0,5	✓	3,18 €
JFM1012-09	10 ^{+0,025 +0,083}	12,0	18,0	9	1,00	0,5	✓	3,95 €
JFM1012-12	10 ^{+0,025 +0,083}	12,0	18,0	12	1,00	0,5	✓	4,01 €
JFM1012-15	10 ^{+0,025 +0,083}	12,0	18,0	15	1,00	0,5	✓	3,41 €
JFM1214-09	12 ^{+0,032 +0,102}	14,0	20,0	9	1,00	0,8	✓	3,81 €
JFM1214-12	12 ^{+0,032 +0,102}	14,0	20,0	12	1,00	0,8	✓	4,46 €
JFM1214-15	12 ^{+0,032 +0,102}	14,0	20,0	15	1,00	0,8	✓	4,71 €
JFM1416-12	14 ^{+0,032 +0,102}	16,0	22,0	12	1,00	0,8	-	4,39 €
JFM1416-17	14 ^{+0,032 +0,102}	16,0	22,0	17	1,00	0,8	✓	5,06 €
JFM1521-20	15 ^{+0,032 +0,102}	21,0	27,0	20	3,00	0,8	✓	7,63 €
JFM1618-17	16 ^{+0,032 +0,102}	18,0	24,0	17	1,00	0,8	✓	5,48 €
JFM1820-22	18 ^{+0,032 +0,102}	20,0	26,0	22	1,00	0,8	✓	5,84 €
JFM2023-21	20 ^{+0,040 +0,124}	23,0	30,0	21	1,00	0,8	✓	6,67 €
JFM2528-21	25 ^{+0,040 +0,124}	28,0	35,0	21	1,50	0,8	✓	7,30 €

*Depending on availability - Dimensions in mm

Our other products




BoWex® curved tooth gear coupling, Nylon

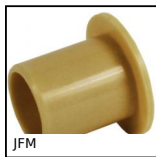

Flanged polymer bush, Universal polymer



Steel bevel gear, 2:1

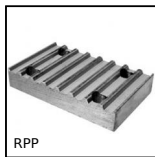

Connecting plate for RPP type timing belts, RRP5



 
Universal adjustable guide support bracket, Stainless steel




Accessories, Fixing kit



Adjustment bushing for half-rail guide, Adjustment bushing



Manual lifting tables, 3kg

 

Keysteel, Stainless steel - Keystock



Spur gear - precision range, Stainless steel

 


Lock for latch clamp, Strike plate




Conveyor wheel, Plastic

Complementary products



 Cylindrical polymer bush, Universal polymer



Flanged polymer bush, Food grade polymer