

## Economy range

**KBww**  
**KBSww**

- Precise guiding accuracy
- Integrated seals
- Working temperature range -20°C to +80°C
- Material:


Housing: Steel or stainless steel

Ball raceway: Polyamide

### info.

- Should be used with **Z-A** or **Z-B** hardened and ground shafts

**Economy range**

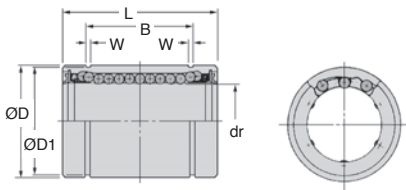

### DISCOUNTS

Qty	1+	5+	10+	25+
Disc.	List	-6%	-30%	On request

Part number	dr	ØD	L	B	W	D1	Loads		Stock*	Price each 1 to 4
							Dynamic C (N)	Static Co (N)		
<b>Steel with polyamide raceway</b>										
KB-8-WW	8 <sup>0/+0,008</sup>	16 <sup>0/-0,008</sup>	25 <sup>0/-0,2</sup>	16,5 <sup>0/+0,2</sup>	1,10	15,2	265	402	✓	9,17 €
KB-12-WW	12 <sup>0/+0,008</sup>	22 <sup>0/-0,009</sup>	32 <sup>0/-0,2</sup>	22,9 <sup>0/+0,2</sup>	1,30	21,0	510	784	✓	10,70 €
KB-16-WW	16 <sup>-0,001/+0,009</sup>	26 <sup>0/-0,009</sup>	36 <sup>0/-0,2</sup>	24,9 <sup>0/+0,2</sup>	1,30	24,9	578	892	✓	12,09 €
KB-20-WW	20 <sup>-0,001/+0,009</sup>	32 <sup>0/-0,011</sup>	45 <sup>0/-0,2</sup>	31,5 <sup>0/+0,2</sup>	1,60	30,3	862	1370	✓	12,74 €
KB-25-WW	25 <sup>-0,001/+0,011</sup>	40 <sup>0/-0,011</sup>	58 <sup>0/-0,3</sup>	44,1 <sup>0/+0,3</sup>	1,85	37,5	980	1570	✓	22,29 €
KB-30-WW	30 <sup>-0,001/+0,011</sup>	47 <sup>0/-0,011</sup>	68 <sup>0/-0,3</sup>	52,1 <sup>0/+0,3</sup>	1,85	44,5	1570	2740	✓	25,77 €
KB-40-WW	40 <sup>-0,002/+0,013</sup>	62 <sup>0/-0,013</sup>	80 <sup>0/-0,3</sup>	60,6 <sup>0/+0,3</sup>	2,15	59,0	2160	4020	✓	44,19 €
<b>Stainless steel with polyamide raceway</b>										
KBS-12-WW	12 <sup>0/-0,008</sup>	22 <sup>0/-0,009</sup>	32 <sup>0/-0,2</sup>	22,9 <sup>0/+0,2</sup>	1,30	21,00	510	784	✓	29,16 €
KBS-16-WW	16 <sup>-0,001/+0,009</sup>	26 <sup>0/-0,009</sup>	36 <sup>0/-0,2</sup>	24,9 <sup>0/+0,2</sup>	1,30	24,90	578	892	✓	40,83 €
KBS-20-WW	20 <sup>-0,001/+0,011</sup>	32 <sup>0/-0,011</sup>	45 <sup>0/-0,2</sup>	31,5 <sup>0/+0,2</sup>	1,60	30,30	862	1370	✓	47,87 €
KBS-25-WW	25 <sup>-0,001/+0,011</sup>	40 <sup>0/-0,011</sup>	58 <sup>0/-0,3</sup>	44,1 <sup>0/+0,3</sup>	1,85	37,50	980	1570	✓	70,06 €
KBS-30-WW	30 <sup>-0,001/+0,011</sup>	47 <sup>0/-0,011</sup>	68 <sup>0/-0,3</sup>	52,1 <sup>0/+0,3</sup>	1,85	44,50	1570	2740	-	93,44 €
KBS-40-WW	40 <sup>-0,002/+0,013</sup>	62 <sup>0/-0,013</sup>	80 <sup>0/-0,3</sup>	60,6 <sup>0/+0,3</sup>	2,15	59,00	2160	4020	-	151,83 €

\*Depending on availability - Dimensions in mm

## Our other products



303 Stainless steel ball pin, 303 Stainless steel



Arm with rotating handle, Square bore steel



Self-locking nut, Steel



Stainless steel/Polymer flanged bearing, Polymer and stainless steel



Drive sprocket for slat chain, Ranges 821 and 805



Speed controller 5A accessories, Kit of 4 cables for DC motor



Assembly tool for carrier ball, Mounting tool



Male clevis end, Steel short



Stainless steel gas spring, Stainless steel



T type timing belt per metre, T5 Steel cored



Cap for square tube to be welded, To be



Moulded plastic bevel gear (nylon), 1:1

## Complementary products



Shaft for linear guides, Hardened ground steel



Shaft for linear guides, Hardened ground stainless steel



Shaft for linear guides, Hardened ground steel