


KGS

Rolled ball screw, class 7

- **Rolled ballscrew**
- **Material:**
Polished steel, Cf53 or Cf60 induction hardened.
- **Hardness:** 60±2 HRC

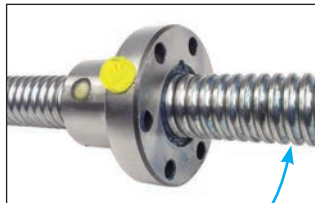

Options

- Ends can be machined to customer requirements
- Cut to length
- Other diameters available (up to 80mm)

Accessories

 
- See **GBS-F, GBS-Z, GBM-F, GBM-Z** nuts



GBS nut

KGS screw

Extended range,
new sizes available



DISCOUNTS

Qty	1+	2+	6+	11+
Disc.	List	-7%	-13%	On request

Part number	For Movement		Unmachined screw		L (mm)	L max (mm)	Weight/m (kg)	Stock*	Price each
	Ød0 (mm)	screw per turn	Ød1	Ød2					
KGS1605-1000TR7	16	5	15,5	12,9	1000	3000	1,26	✓	85,76 €
KGS2005-1000TR7	20	5	19,5	16,9	1000	6000	1,26	✓	115,05 €
KGS2020-1000TR7	20	20	19,5	16,9	1000	6000	3,04	-	124,98 €
KGS2050-1000TR7	20	50	19,1	16,5	1000	6000	2,07	-	133,18 €
KGS2505-1000TR7	25	5	24,5	21,9	1000	6000	3,33	✓	154,46 €
KGS3205-1000TR7	32	5	31,5	28,9	1000	6000	5,61	✓	216,36 €
KGS3210-1000TR7	32	10	31,5	28,9	1000	6000	5,61	-	217,26 €
KGS3220-1000TR7	32	20	31,4	28,7	1000	6000	5,61	-	224,73 €
KGS3240-1000TR7	32	40	32,6	28,9	1000	6000	5,61	-	229,04 €
KGS4005-1000TR7	40	5	39,5	36,9	1000	6000	9,03	✓	305,37 €
KGS4010-1000TR7	40	10	39,5	34,1	1000	6000	8,33	-	286,99 €
KGS5010-1000TR7	50	10	49,2	44	1000	6000	13,48	-	387,31 €
KGS5020-1000TR7	50	20	49,4	44	1000	6000	13,48	-	431,55 €
KGS6310-1000TR7	63	10	62,2	57	1000	6000	22,04	-	612,27 €

*Depending on availability - Dimensions in mm

Our other products



MLY

Bow shackle with eye bolt, Steel



VDSCB

Sliding lock adjustment system, Blocking wedge for sliding lock for ...



ZG0

Plastic spur gear, Machined plastic (delrin)



T2,5-BAR

T type tooth bar stock, T2.5



CHAuss

Screwed hinge, 270°



PTAF80-PAMF80

Articulated fixable foot with pressed base Ø80, Ø 80



CDP

Flanged drill bushing, Steel



INS_SS

Self tapping stainless steel insert, Stainless steel



 
PRF_PA

Angle plate for aluminium profile, Adjustable plate




SLV

Vertical toggle clamp, Vertical Lever Clamp - steel



KITbuh

24V DC motorisation kit, Planetary gears

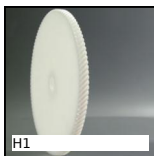

H1

Crossed helical gear crossed axis at 90°, Machined plastic (delrin)

Complementary products



GBS

Nut for ballscrew, Flanged ballscrew nut



GBSz

Cylindrical ballscrew nut, Cylindrical leadscrew nut