


KGS

Rolled ball screw, class 7

- **Rolled ballscrew**
- **Material:**
Polished steel, Cf53 or Cf60 induction hardened.
- **Hardness:** 60±2 HRC

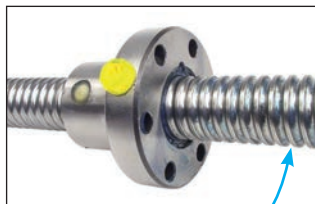

Options

- Ends can be machined to customer requirements
- Cut to length
- Other diameters available (up to 80mm)

Accessories

 
- See **GBS-F, GBS-Z, GBM-F, GBM-Z** nuts



GBS nut

KGS screw

Extended range,
new sizes available



DISCOUNTS

Qty	1+	2+	6+	11+
Disc.	List	-7%	-13%	On request

Part number	For Movement		Unmachined screw		L (mm)	L max (mm)	Weight/m (kg)	Stock*	Price each
	Ød0 (mm)	screw per turn	Ød1	Ød2					
KGS1605-1000TR7	16	5	15,5	12,9	1000	3000	1,26	✓	85,76 €
KGS2005-1000TR7	20	5	19,5	16,9	1000	6000	1,26	✓	115,05 €
KGS2020-1000TR7	20	20	19,5	16,9	1000	6000	3,04	-	124,98 €
KGS2050-1000TR7	20	50	19,1	16,5	1000	6000	2,07	-	133,18 €
KGS2505-1000TR7	25	5	24,5	21,9	1000	6000	3,33	✓	154,46 €
KGS3205-1000TR7	32	5	31,5	28,9	1000	6000	5,61	✓	216,36 €
KGS3210-1000TR7	32	10	31,5	28,9	1000	6000	5,61	-	217,26 €
KGS3220-1000TR7	32	20	31,4	28,7	1000	6000	5,61	-	224,73 €
KGS3240-1000TR7	32	40	32,6	28,9	1000	6000	5,61	-	229,04 €
KGS4005-1000TR7	40	5	39,5	36,9	1000	6000	9,03	✓	305,37 €
KGS4010-1000TR7	40	10	39,5	34,1	1000	6000	8,33	-	286,99 €
KGS5010-1000TR7	50	10	49,2	44	1000	6000	13,48	-	387,31 €
KGS5020-1000TR7	50	20	49,4	44	1000	6000	13,48	-	431,55 €
KGS6310-1000TR7	63	10	62,2	57	1000	6000	22,04	-	612,27 €

*Depending on availability - Dimensions in mm

Our other products



LACM_SS
Stainless steel cam
lever, Female



CHTRP
Single and dual
output gearboxes, Up
to 87,3Nm



PM3
Worm and wheel set,
Hardened steel




ACLBDB
Closing mechanism
for aluminium profile,
Dual ball catch



PSG125S
Spur gear - precision
range, Stainless steel
316



 V3RA_PT
3-spoked handwheel
with handle,
Polyamide



PRF LIS
Door seal for
aluminium profile,
Black NBR



EBC
Cap nut Hygienic
Design®, Compact



WW16
Drylin® W slide, slide
assembly



NSO
Housing for open
linear bearing,
Opened - long



PP60
Worm and wheel gear
reducer, from 17.80
to 34 Nm



CHMR90
Worm and wheel gear
reducer, up to 540
Nm

Complementary products



GBS
Nut for ballscrew,
Flanged ballscrew nut



GBSz
Cylindrical ballscrew
nut, Cylindrical
leadscrew nut