

# 24V dc motorisation kit

## KITDOG

## Worm and wheel

- The kit comprises:
  - 1 motorised gearbox DOG319
  - 1 servoamplifier FIRSTDC-1Q
  - 1 potentiometer MDPOT-10T/10K
  - 1 power supply ALIDR120-2(please refer to product pages for full technical details)
- Reduced size
- Low noise
- Solid design
- Powerfull



### Application

- Industrial drives

### Advantages

- Complete set
- Easy to set up

### DISCOUNTS

Qty	1+	6+	10+
Disc. List	-7%	On request	

Part number	Motor used	Max speed (rpm)	Max torque (Nm)	Price each 1 to 9
KIT-DOG-30	DOG319-24-30	30	9	537,41 €
KIT-DOG-45	DOG319-24-45	45	9	537,41 €
KIT-DOG-85	DOG319-24-85	85	4	537,41 €

Dimensions in mm

## Our other products



PC575K  
Chain sprocket with  
hardened teeth,  
19.05mm (DIN12B-1)



NIN  
Self-locking nut, Steel



HAR9  
Captive C washer, DIN  
6371




SER  
Magnetic doorstop for  
aluminium profile,  
Magnetic doorstop



EHD08-9  
Internal epicyclic  
servo reducers, from  
35 to 50 Nm



PTAf80-PAMF80  
Articulated fixable  
foot with pressed  
base Ø80, Ø 80

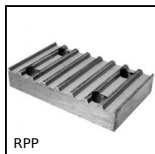

RPP  
Connecting plate for  
RPP type timing belts,  
RPP14



LF  
Precision locknut,  
Precision locknut



BCFH  
Mushroom headed  
button Hygienic



DP  
Dowel pin, Solid ISO  
2338



RDE-B  
Sealing washer  
Hygienic Usit®.



GARBAB  
Lock pin for clamping,  
Ball lock pin

## Complementary products



KITbuh  
24V DC motorisation  
kit, Planetary gears



DOG319  
Motor-gearbox 12V  
and 24V DC, from 4 to  
9 Nm