


KK

Steel

- Mechanical interlock
- Type A
- Keyway required in associated parts
- Material: Steel C45
- **Not sold individually, please contact us for details**

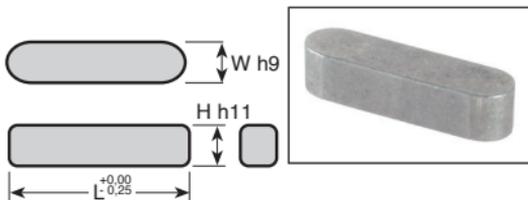

Options

- Also exists in stainless steel (316) and imperial sizes
- Also exists in Box (tome 1 p.632)

DISCOUNTS

Qty	1+	20+	50+	100+	200+	500+	1000+
Disc.	List	-45%	-55%	-65%	-70%	-80%	On request



Part number	W (h9)	H (h11)	L	Stock*	Price each 1 to 5
KK2-10	2	2	10	✓	1,00 €
KK2-14	2	2	14	✓	2,58 €
KK2-20	2	2	20	✓	1,34 €
KK2-22	2	2	22	✓	2,63 €
KK3-8	3	3	8	✓	0,65 €
KK3-10	3	3	10	✓	0,72 €
KK3-12	3	3	12	✓	0,69 €
KK3-15	3	3	15	✓	1,13 €
KK3-20	3	3	20	✓	0,74 €
KK3-30	3	3	30	✓	1,29 €
KK3-40	3	3	40	✓	1,13 €
KK4-8	4	4	8	✓	0,65 €
KK4-10	4	4	10	✓	0,76 €
KK4-12	4	4	12	✓	0,88 €
KK4-15	4	4	15	✓	0,99 €
KK4-16	4	4	16	✓	0,65 €
KK4-20	4	4	20	✓	1,18 €
KK4-25	4	4	25	✓	1,23 €
KK5-10	5	5	10	✓	0,76 €
KK5-12	5	5	12	-	2,30 €
KK5-14	5	5	14	✓	0,82 €
KK5-16	5	5	16	✓	0,79 €
KK5-18	5	5	18	✓	0,65 €
KK5-20	5	5	20	✓	1,30 €
KK5-25	5	5	25	✓	0,86 €
KK5-30	5	5	30	✓	1,04 €
KK5-35	5	5	35	✓	1,28 €
KK5-40	5	5	40	✓	1,80 €
KK5-50	5	5	50	✓	1,31 €
KK6-12	6	6	12	✓	0,97 €
KK6-14	6	6	14	✓	1,34 €
KK6-16	6	6	16	✓	0,89 €

Part number	W (h9)	H (h11)	L	Stock*	Price each 1 to 19
KK6-18	6	6	18	✓	0,89 €
KK6-20	6	6	20	✓	1,00 €
KK6-25	6	6	25	✓	1,22 €
KK6-28	6	6	28	✓	1,18 €
KK6-30	6	6	30	✓	1,54 €
KK6-32	6	6	32	✓	1,23 €
KK6-36	6	6	36	✓	1,13 €
KK6-45	6	6	45	✓	1,31 €
KK6-50	6	6	50	✓	1,81 €
KK8-7-18	8	7	18	✓	1,19 €
KK8-7-20	8	7	20	✓	1,19 €
KK8-7-22	8	7	22	✓	2,57 €
KK8-7-25	8	7	25	✓	1,22 €
KK8-7-30	8	7	30	✓	1,65 €
KK8-7-40	8	7	40	✓	1,59 €
KK8-7-45	8	7	45	✓	2,80 €
KK8-7-50	8	7	50	✓	1,87 €
KK10-8-20	10	8	20	✓	1,45 €
KK10-8-28	10	8	28	✓	1,78 €
KK10-8-30	10	8	30	✓	2,24 €
KK10-8-36	10	8	36	✓	3,66 €
KK10-8-40	10	8	40	✓	2,70 €
KK10-8-45	10	8	45	✓	2,05 €
KK10-8-50	10	8	50	✓	2,75 €
KK12-8-36	12	8	36	✓	2,93 €
KK12-8-40	12	8	40	✓	2,61 €
KK12-8-45	12	8	45	✓	2,80 €
KK12-8-50	12	8	50	✓	3,18 €
KK12-8-56	12	8	56	-	2,80 €
KK12-8-60	12	8	60	✓	3,74 €
KK14-9-50	14	9	50	✓	4,11 €
KK14-9-70	14	9	70	✓	5,61 €

*Depending on availability - Dimensions in mm

- Mechanical interlock
- Type A
- Keyway required in associated parts
- Material: Stainless steel 316Ti (60 daN/mm²)
- **Not sold individually, please contact us for details**
- Also exists in Box (tome **1** p.632)

stainless steel

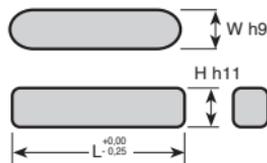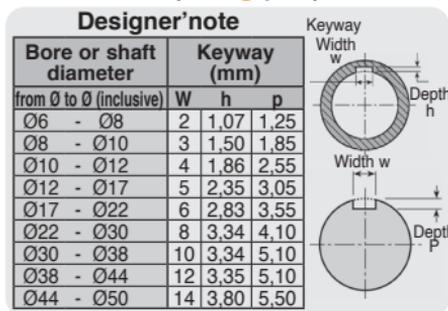

DISCOUNTS

Qty	1+	6+	20+	50+	100+	200+
Disc.	List	-15%	-45%	-55%	-65%	On request

Part number	Width W (h9)	Height H (h11)	Length L	Stock*	Price each 1 to 5 parts
KK2-20SS	2	2	20	✓	6,41 €
KK3-10SS	3	3	10	✓	2,25 €
KK3-20SS	3	3	20	✓	2,46 €
KK4-10SS	4	4	10	✓	2,76 €
KK4-12SS	4	4	12	✓	1,70 €
KK4-18SS	4	4	18	✓	2,82 €
KK4-20SS	4	4	20	✓	3,03 €
KK4-25SS	4	4	25	✓	3,20 €
KK5-10SS	5	5	10	✓	2,94 €
KK5-20SS	5	5	20	✓	3,50 €
KK5-25SS	5	5	25	✓	3,72 €
KK5-30SS	5	5	30	✓	4,21 €
KK6-10SS	6	6	10	✓	3,50 €
KK6-20SS	6	6	20	✓	4,19 €
KK6-25SS	6	6	25	✓	4,73 €
KK6-30SS	6	6	30	✓	5,44 €
KK8-7-20SS	8	7	20	✓	5,68 €
KK8-7-25SS	8	7	25	✓	6,41 €
KK8-7-30SS	8	7	30	✓	7,39 €
KK8-7-35SS	8	7	35	✓	8,05 €
KK10-8-20SS	10	8	20	✓	7,62 €
KK10-8-25SS	10	8	25	✓	8,86 €
KK10-8-30SS	10	8	30	✓	10,34 €
KK10-8-35SS	10	8	35	✓	11,31 €
KK12-8-20SS	12	8	20	-	12,33 €
KK12-8-25SS	12	8	25	-	12,26 €
KK12-8-30SS	12	8	30	✓	12,33 €
KK12-8-35SS	12	8	35	-	13,27 €

*Depending on availability - Dimensions in mm