


# Rounded end feather key **DIN 6885** **Ste** **DIN** **Stock**

## KK

## Steel

- Mechanical interlock
- Type A (2 round ends)
- Keyway required in associated parts
- Material: Steel C45
- **Not sold individually, please contact us for details**

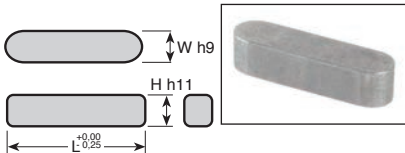

### Options

- Also exists in stainless steel (316) and imperial sizes

### DISCOUNTS

Qty	1+	20+	50+	100+	200+	500+	1000+
Disc.	List	-45%	-55%	-65%	-70%	-80%	On request

Part number	W (h9)	H (h11)	L	Stock*	Price each 1 to 5
KK2-10	2	2	10	✓	0,55 €
KK2-14	2	2	14	✓	0,55 €
KK2-20	2	2	20	✓	0,55 €
KK2-22	2	2	22	✓	0,55 €
KK3-8	3	3	8	✓	0,42 €
KK3-10	3	3	10	✓	0,46 €
KK3-12	3	3	12	✓	0,42 €
KK3-15	3	3	15	✓	0,42 €
KK3-20	3	3	20	✓	0,43 €
KK3-30	3	3	30	✓	0,42 €
KK3-40	3	3	40	✓	0,42 €
KK4-8	4	4	8	✓	0,42 €
KK4-10	4	4	10	✓	0,42 €
KK4-12	4	4	12	✓	0,42 €
KK4-15	4	4	15	✓	0,42 €
KK4-16	4	4	16	✓	0,42 €
KK4-20	4	4	20	✓	0,42 €
KK4-25	4	4	25	✓	0,43 €
KK5-10	5	5	10	✓	0,42 €
KK5-12	5	5	12	-	1,58 €
KK5-14	5	5	14	✓	0,42 €
KK5-16	5	5	16	✓	0,42 €
KK5-18	5	5	18	✓	0,42 €
KK5-20	5	5	20	✓	0,44 €
KK5-25	5	5	25	✓	0,42 €
KK5-30	5	5	30	✓	0,46 €
KK5-35	5	5	35	✓	0,55 €
KK5-40	5	5	40	✓	0,55 €
KK5-50	5	5	50	✓	0,50 €
KK6-12	6	6	12	✓	0,55 €
KK6-14	6	6	14	✓	0,55 €
KK6-16	6	6	16	✓	0,55 €

Part number	W (h9)	H (h11)	L	Stock*	Price each 1 to 19
KK6-18	6	6	18	✓	0,55 €
KK6-20	6	6	20	✓	0,55 €
KK6-25	6	6	25	✓	0,55 €
KK6-28	6	6	28	✓	0,55 €
KK6-30	6	6	30	✓	0,55 €
KK6-32	6	6	32	✓	0,55 €
KK6-36	6	6	36	✓	0,57 €
KK6-45	6	6	45	✓	0,73 €
KK6-50	6	6	50	✓	0,66 €
KK8-7-18	8	7	18	✓	0,73 €
KK8-7-20	8	7	20	✓	0,73 €
KK8-7-22	8	7	22	✓	0,73 €
KK8-7-25	8	7	25	✓	0,75 €
KK8-7-30	8	7	30	✓	0,73 €
KK8-7-40	8	7	40	✓	0,84 €
KK8-7-45	8	7	45	✓	1,70 €
KK8-7-50	8	7	50	✓	0,90 €
KK10-8-20	10	8	20	✓	0,89 €
KK10-8-28	10	8	28	✓	0,89 €
KK10-8-30	10	8	30	✓	1,03 €
KK10-8-36	10	8	36	✓	1,03 €
KK10-8-40	10	8	40	✓	1,03 €
KK10-8-45	10	8	45	✓	1,22 €
KK10-8-50	10	8	50	✓	1,22 €
KK12-8-36	12	8	36	✓	1,36 €
KK12-8-40	12	8	40	✓	1,36 €
KK12-8-45	12	8	45	✓	1,52 €
KK12-8-50	12	8	50	✓	1,57 €
KK12-8-56	12	8	56	-	1,70 €
KK12-8-60	12	8	60	✓	1,70 €
KK14-9-50	14	9	50	✓	1,88 €
KK14-9-70	14	9	70	✓	2,64 €

\*Depending on availability - Dimensions in mm

## Our other products



LVT  
Miniature motorised actuator 2A, 2 ampers



GTCSS  
Belt tensioner, For use in hostile environments



CQA30  
Accessory for adjustment slide-system, 30



RAG  
Roller guide,



SLH-M  
Nut for toggle clamp, Round ended nut for SLH/SLV clamp



PRF\_GAL  
Roller for aluminium profile, Fixing kit for roller eccentric



PRF\_GAL  
Roller for aluminium profile, Flat roller



CSSSS  
Stainless steel spherical bearing, Stainless steel / PTFE



PRF\_PL\_4590  
Joining plate for aluminium profile, Joint plate - 45x90



UCFL\_SS  
Stainless steel flanged bearing, Stainless steel



DBL880  
Idler for slat top chain, Ranges 880 and 881

 


PPF  
Indexing plunger with flange, with drilled flange

## Complementary products



KKSS  
Rounded end feather key, Stainless steel



KS  
Keysteel, Steel - Keystock



BOXKK  
Boxed set of DIN6885A keys, Boxed set - Steel or stainless steel



PCS75K  
Chain sprocket with hardened teeth, 19.05mm (DIN12B-1)