 



- Mechanical interlock
- Type A (2 round ends)
- Keyway required in associated parts
- Material: Key steel XC48 60 daN/mm<sup>2</sup>
- **Not sold individually, please contact us for details**

## Designer's note

Bore or shaft diameter from Ø to Ø (inclusive)	Keyway (mm)		
	W	h	p
Ø6 - Ø8	2	1,07	1,25
Ø8 - Ø10	3	1,50	1,85
Ø10 - Ø12	4	1,86	2,55
Ø12 - Ø17	5	2,35	3,05
Ø17 - Ø22	6	2,83	3,55
Ø22 - Ø30	8	3,34	4,10
Ø30 - Ø38	10	3,34	5,10
Ø38 - Ø44	12	3,35	5,10
Ø44 - Ø50	14	3,80	5,50



stainless steel

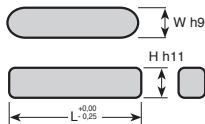

## DISCOUNTS

Qty	1+	6+	20+	50+	100+	200+
Disc.	List	-15%	-45%	-55%	-65%	On request

Part number	Width W (h9)	Height H (h11)	Length L	Stock*	Price each 1 to 5 parts
KK2-20SS	2	2	20	✓	3,86 €
KK3-10SS	3	3	10	✓	1,36 €
KK3-20SS	3	3	20	✓	1,49 €
KK4-10SS	4	4	10	✓	1,66 €
KK4-12SS	4	4	12	✓	1,03 €
KK4-18SS	4	4	18	✓	1,71 €
KK4-20SS	4	4	20	✓	1,84 €
KK4-25SS	4	4	25	✓	1,94 €
KK5-10SS	5	5	10	✓	1,78 €
KK5-20SS	5	5	20	✓	2,11 €
KK5-25SS	5	5	25	✓	2,24 €
KK5-30SS	5	5	30	✓	2,55 €
KK6-10SS	6	6	10	✓	2,11 €
KK6-20SS	6	6	20	✓	2,54 €
KK6-25SS	6	6	25	✓	2,84 €
KK6-30SS	6	6	30	✓	3,29 €
KK8-7-20SS	8	7	20	✓	3,41 €
KK8-7-25SS	8	7	25	✓	3,86 €
KK8-7-30SS	8	7	30	✓	4,44 €
KK8-7-35SS	8	7	35	✓	4,82 €
KK10-8-20SS	10	8	20	✓	4,59 €
KK10-8-25SS	10	8	25	✓	5,31 €
KK10-8-30SS	10	8	30	✓	6,19 €
KK10-8-35SS	10	8	35	✓	6,77 €
KK12-8-20SS	12	8	20	-	7,40 €
KK12-8-25SS	12	8	25	✓	7,35 €
KK12-8-30SS	12	8	30	✓	7,40 €
KK12-8-35SS	12	8	35	✓	7,95 €

\*Depending on availability - Dimensions in mm

## Our other products



PCS5055  
Chain sprocket -  
Stainless steel,  
12.7mm (DIN 08B-1)



CHINV  
Invisible hinge,  
Invisible - Opening up  
to 90°



LRR-53  
Spring loaded latch,  
Spring return latch -  
steel



CABtool  
Fitting cable tools,  
Cutting tools



PCS62  
Chain sprocket - steel,  
15.875 (DIN 10B-1)



 
SEV  
Vertical stirrup toggle  
clamp, Vertical Latch  
Clamp - steel



NKIB  
Combined bearing  
with inner ring, Axial  
load in both directions



HBM  
Adjustment bushing  
for half-rail guide,  
Adjustment bushing



G1  
Steel spur gear, Steel  
20NCD2



RJUM05  
Drylin R® linear  
bearing housing,



PT882  
Drive sprocket for slat  
top chain, Range 882




YG3  
HEAVY DUTY spur  
gear, Steel 35NCD6

## Complementary products



 BOXKK  
Boxed set of  
DIN6885A keys,  
Boxed set - Steel or  
stainless steel



KS  
Keysteel, Stainless  
steel - Keystock