 



- Mechanical interlock
- Type A (2 round ends)
- Keyway required in associated parts
- Material: Key steel XC48 60 daN/mm²
- **Not sold individually, please contact us for details**

Designer's note

Bore or shaft diameter from Ø to Ø (inclusive)	Keyway (mm)		
	W	h	p
Ø6 - Ø8	2	1,07	1,25
Ø8 - Ø10	3	1,50	1,85
Ø10 - Ø12	4	1,86	2,55
Ø12 - Ø17	5	2,35	3,05
Ø17 - Ø22	6	2,83	3,55
Ø22 - Ø30	8	3,34	4,10
Ø30 - Ø38	10	3,34	5,10
Ø38 - Ø44	12	3,35	5,10
Ø44 - Ø50	14	3,80	5,50



stainless steel

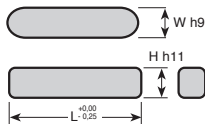

DISCOUNTS

Qty	1+	6+	20+	50+	100+	200+
Disc.	List	-15%	-45%	-55%	-65%	On request

Part number	Width W (h9)	Height H (h11)	Length L	Stock*	Price each 1 to 5 parts
KK2-20SS	2	2	20	✓	3,86 €
KK3-10SS	3	3	10	✓	1,36 €
KK3-20SS	3	3	20	✓	1,49 €
KK4-10SS	4	4	10	✓	1,66 €
KK4-12SS	4	4	12	✓	1,03 €
KK4-18SS	4	4	18	✓	1,71 €
KK4-20SS	4	4	20	✓	1,84 €
KK4-25SS	4	4	25	✓	1,94 €
KK5-10SS	5	5	10	✓	1,78 €
KK5-20SS	5	5	20	✓	2,11 €
KK5-25SS	5	5	25	✓	2,24 €
KK5-30SS	5	5	30	✓	2,55 €
KK6-10SS	6	6	10	✓	2,11 €
KK6-20SS	6	6	20	✓	2,54 €
KK6-25SS	6	6	25	✓	2,84 €
KK6-30SS	6	6	30	✓	3,29 €
KK8-7-20SS	8	7	20	✓	3,41 €
KK8-7-25SS	8	7	25	✓	3,86 €
KK8-7-30SS	8	7	30	✓	4,44 €
KK8-7-35SS	8	7	35	✓	4,82 €
KK10-8-20SS	10	8	20	✓	4,59 €
KK10-8-25SS	10	8	25	✓	5,31 €
KK10-8-30SS	10	8	30	✓	6,19 €
KK10-8-35SS	10	8	35	✓	6,77 €
KK12-8-20SS	12	8	20	-	7,40 €
KK12-8-25SS	12	8	25	✓	7,35 €
KK12-8-30SS	12	8	30	✓	7,40 €
KK12-8-35SS	12	8	35	✓	7,95 €

 
*Depending on availability - Dimensions in mm

Our other products



RPC

Wheel, Polyamide



ACL-PR

Joining plate for aluminium profile, Right angled connection



GBSz

Cylindrical ballscrew nut, Cylindrical leadscrew nut



 
PAMF100EB

Articulated foot with sheet metal base Ø100, Articulated foot



CHAEpac

Square decorative screwed hinges, carbon fibre reinforced



AC

Strike for toggle latch, 15mm



AC

Strike for toggle latch, 13mm



SEH

Horizontal stirrup toggle clamp, Horizontal stirrup clamp - steel



PSG1

Spur gear - precision range, Pre-hardened Steel 35NCD6



 
BPFss

Pressed stainless steel flange bearing, Stainless steel



ES

Support base (tripod), Plastic



LWH

 
High rigidity linear slide, Chariot - from 9320 N to 71300 N

Complementary products



BOXKK

Boxed set of DIN6885A keys, Boxed set - Steel or stainless steel



KS

Keysteel, Stainless steel - Keystock



KK

Rounded end feather key, Steel