 



- Mechanical interlock
- Type A (2 round ends)
- Keyway required in associated parts
- Material: Key steel XC48 60 daN/mm<sup>2</sup>
- **Not sold individually, please contact us for details**

## Designer's note

Bore or shaft diameter from Ø to Ø (inclusive)	Keyway (mm)		
	W	h	p
Ø6 - Ø8	2	1,07	1,25
Ø8 - Ø10	3	1,50	1,85
Ø10 - Ø12	4	1,86	2,55
Ø12 - Ø17	5	2,35	3,05
Ø17 - Ø22	6	2,83	3,55
Ø22 - Ø30	8	3,34	4,10
Ø30 - Ø38	10	3,34	5,10
Ø38 - Ø44	12	3,35	5,10
Ø44 - Ø50	14	3,80	5,50



stainless steel

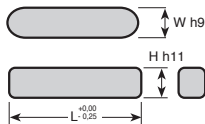

## DISCOUNTS

Qty	1+	6+	20+	50+	100+	200+
Disc.	List	-15%	-45%	-55%	-65%	On request

Part number	Width W (h9)	Height H (h11)	Length L	Stock*	Price each 1 to 5 parts
KK2-20SS	2	2	20	✓	3,86 €
KK3-10SS	3	3	10	✓	1,36 €
KK3-20SS	3	3	20	✓	1,49 €
KK4-10SS	4	4	10	✓	1,66 €
KK4-12SS	4	4	12	✓	1,03 €
KK4-18SS	4	4	18	✓	1,71 €
KK4-20SS	4	4	20	✓	1,84 €
KK4-25SS	4	4	25	✓	1,94 €
KK5-10SS	5	5	10	✓	1,78 €
KK5-20SS	5	5	20	✓	2,11 €
KK5-25SS	5	5	25	✓	2,24 €
KK5-30SS	5	5	30	✓	2,55 €
KK6-10SS	6	6	10	✓	2,11 €
KK6-20SS	6	6	20	✓	2,54 €
KK6-25SS	6	6	25	✓	2,84 €
KK6-30SS	6	6	30	✓	3,29 €
KK8-7-20SS	8	7	20	✓	3,41 €
KK8-7-25SS	8	7	25	✓	3,86 €
KK8-7-30SS	8	7	30	✓	4,44 €
KK8-7-35SS	8	7	35	✓	4,82 €
KK10-8-20SS	10	8	20	✓	4,59 €
KK10-8-25SS	10	8	25	✓	5,31 €
KK10-8-30SS	10	8	30	✓	6,19 €
KK10-8-35SS	10	8	35	✓	6,77 €
KK12-8-20SS	12	8	20	-	7,40 €
KK12-8-25SS	12	8	25	✓	7,35 €
KK12-8-30SS	12	8	30	✓	7,40 €
KK12-8-35SS	12	8	35	✓	7,95 €

\*Depending on availability - Dimensions in mm

## Our other products



CFS  
Miniature cam follower, Miniature



PP60  
Worm and wheel gear reducer, from 17.80 to 34 Nm



FAD  
Threaded swivel feet, Swivel feet without anti-slip plate



PP50  
Worm and wheel gear reducer, from 6.50 to 12.80 Nm




AC144  
Strike for toggle latch, 22mm



TBD  
Manual leadscrew table with opposing threads, 5kg



NT122  
Spur gear coaxial gearbox, from 32 to 85 Nm - In-line

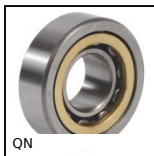

QN  
Single row cylindrical roller bearing, Free outer ring



BAG0  
Locking rings in stainless steel,



PFC  
Fixed rubber levelling foot, Levelling support



BLH40  
Right angled gearbox, from 3 to 10.30 Nm




SLB  
Indexing plunger, stainless steel

## Complementary products



 BOXKK  
Boxed set of DIN6885A keys,  
Boxed set - Steel or stainless steel



KS  
Keysteel, Stainless steel - Keystock



KK  
Rounded end feather key, Steel