 



- Mechanical interlock
- Type A (2 round ends)
- Keyway required in associated parts
- Material: Key steel XC48 60 daN/mm²
- **Not sold individually, please contact us for details**

Designer's note

Bore or shaft diameter from Ø to Ø (inclusive)	Keyway (mm)		
	W	h	p
Ø6 - Ø8	2	1,07	1,25
Ø8 - Ø10	3	1,50	1,85
Ø10 - Ø12	4	1,86	2,55
Ø12 - Ø17	5	2,35	3,05
Ø17 - Ø22	6	2,83	3,55
Ø22 - Ø30	8	3,34	4,10
Ø30 - Ø38	10	3,34	5,10
Ø38 - Ø44	12	3,35	5,10
Ø44 - Ø50	14	3,80	5,50



stainless steel

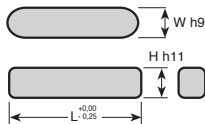

DISCOUNTS

Qty	1+	6+	20+	50+	100+	200+
Disc.	List	-15%	-45%	-55%	-65%	On request

Part number	Width W (h9)	Height H (h11)	Length L	Stock*	Price each 1 to 5 parts
KK2-20SS	2	2	20	✓	3,86 €
KK3-10SS	3	3	10	✓	1,36 €
KK3-20SS	3	3	20	✓	1,49 €
KK4-10SS	4	4	10	✓	1,66 €
KK4-12SS	4	4	12	✓	1,03 €
KK4-18SS	4	4	18	✓	1,71 €
KK4-20SS	4	4	20	✓	1,84 €
KK4-25SS	4	4	25	✓	1,94 €
KK5-10SS	5	5	10	✓	1,78 €
KK5-20SS	5	5	20	✓	2,11 €
KK5-25SS	5	5	25	✓	2,24 €
KK5-30SS	5	5	30	✓	2,55 €
KK6-10SS	6	6	10	✓	2,11 €
KK6-20SS	6	6	20	✓	2,54 €
KK6-25SS	6	6	25	✓	2,84 €
KK6-30SS	6	6	30	✓	3,29 €
KK8-7-20SS	8	7	20	✓	3,41 €
KK8-7-25SS	8	7	25	✓	3,86 €
KK8-7-30SS	8	7	30	✓	4,44 €
KK8-7-35SS	8	7	35	✓	4,82 €
KK10-8-20SS	10	8	20	✓	4,59 €
KK10-8-25SS	10	8	25	✓	5,31 €
KK10-8-30SS	10	8	30	✓	6,19 €
KK10-8-35SS	10	8	35	✓	6,77 €
KK12-8-20SS	12	8	20	-	7,40 €
KK12-8-25SS	12	8	25	✓	7,35 €
KK12-8-30SS	12	8	30	✓	7,40 €
KK12-8-35SS	12	8	35	✓	7,95 €

*Depending on availability - Dimensions in mm

Our other products



VHTM

Hexagonal headed screw Hygienic Design®, Stainless steel



HRV

V-rail guidance Simple Select® system, Rail with carriage



PRFSRAD

Dual lock for aluminium profile, Quick fitting, self locking door du...



RTE

Rotex®, jaw coupling, Aluminium



GLT3-46A

Telescopic drawer with damper,



MSP38

Masterplate® glueable insert Ø38, Cylindrical Ø38 with tapped ins...



GLB

Small 6 lobe threaded handle - female, Technopolymer - Stainless steel



GLB

Small 6 lobe threaded handle - female, Technopolymer - Brass



BPMc

Stainless steel slotted spring plunger with ceramic ball tip, 303




UCP

Cast iron pillow block bearing, Cast iron



CHM40

 Worm and wheel gear reducer, up to 57 Nm



VAB

 
Ball screw, supplied by the metre, Rolled ball screw, per metre

Complementary products



BOXKK

Boxed set of DIN6885A keys, Boxed set - Steel or stainless steel



KS

Keysteel, Stainless steel - Keystock