


- Typically used when mounting bearings
- To be used with **MB** washers
- Absolutely secure, not removable
- Requires machining of keyway in threaded part of the shaft
- Material: steel

### Accessories

- MB washer (tome 3 p.105)

For axial locking

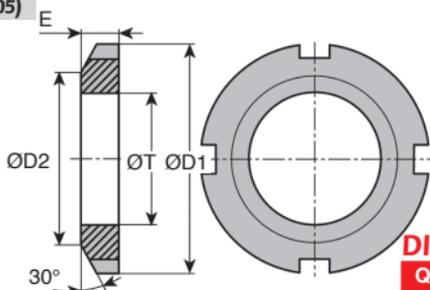

### DISCOUNTS

Qty	1+	10+	20+	50+
Disc.	List	-30%	-50%	On request



Part number	For washer	Thread	ØT	ØD1	ØD2	E	Weight (g)	Stock*	Price each 1 to 9
KM3	MB3	M17x1,0	28	24	24	5	13	✓	3,09 €
KM4	MB4	M20x1,0	32	26	26	6	19	✓	2,78 €
KM5	MB5	M25x1,5	38	32	32	7	25	✓	4,06 €
KM6	MB6	M30x1,5	45	38	38	7	43	✓	4,01 €
KM7	MB7	M35x1,5	52	44	44	8	53	✓	4,95 €
KM8	MB8	M40x1,5	58	50	50	9	85	✓	6,30 €
KM9	MB9	M45x1,5	65	56	56	10	120	✓	6,30 €
KM10	MB10	M50x1,5	70	61	61	11	150	✓	7,01 €
KM11	MB11	M55x2,0	75	67	67	11	160	-	8,66 €
KM12	MB12	M60x2,0	80	73	73	11	170	✓	9,12 €
KM13	MB13	M65x2,0	85	79	79	12	200	-	12,23 €
KM14	MB14	M70x2,0	92	85	85	12	240	-	13,20 €
KM15	MB15	M75x2,0	98	90	90	13	290	-	13,91 €
KM16	MB16	M80x2,0	105	95	95	15	400	✓	18,00 €
KM17	MB17	M85x2,0	110	102	102	16	450	-	22,10 €
KM18	MB18	M90x2,0	120	108	108	16	560	-	25,55 €
KM19	MB19	M95x2,0	125	113	113	17	660	-	26,02 €
KM20	MB20	M100x2,0	130	120	120	18	700	-	32,35 €
KM22	MB22	M110x2,0	145	133	133	19	970	-	39,63 €
KM24	MB24	M120x2,0	155	138	138	20	1080	-	53,61 €
KM26	MB26	M130x2,0	165	149	149	21	1250	-	68,84 €
KM28	MB28	M140x2,0	180	160	160	22	1560	-	77,21 €
KM30	MB30	M150x2,0	195	171	171	25	2030	-	88,30 €

\*Depending on availability - Dimensions in mm

- The tabs around the washer fold down into the tabs on the KM locknut
- The washer being held in place in rotation by the keyway, the system guarantees absolute security
- Material: steel

### Accessories

- KM locknut (tome 3 p.104)

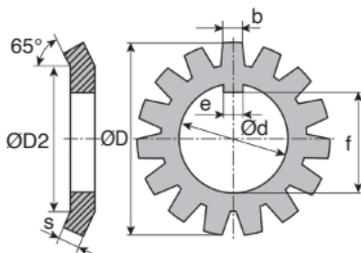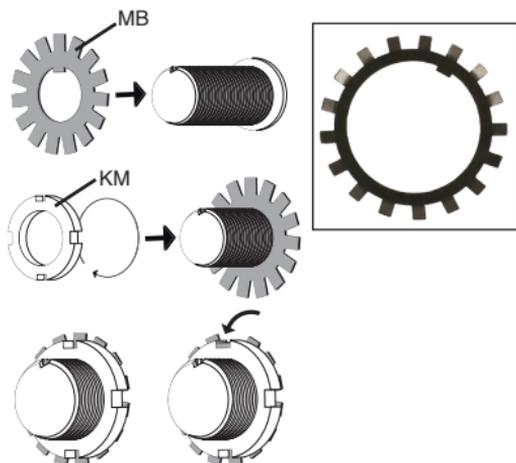

### DISCOUNTS

Qty	1+	10+	20+	50+
Disc.	List	-30%	-50%	On request

Part number	For locknut	Ød	ØD	ØD2	e	f	s	Weight (g)	Stock*	Price each 1 to 9
MB3	KM3	17	32	24	4	15,5	1,00	3,1	✓	0,53 €
MB4	KM4	20	36	26	4	18,5	1,00	3,5	✓	0,53 €
MB5	KM5	25	42	32	5	23,0	1,00	6,4	✓	0,59 €
MB6	KM6	30	49	38	5	27,5	1,25	7,8	✓	0,59 €
MB7	KM7	35	57	44	6	32,5	1,25	10,4	✓	0,72 €
MB8	KM8	40	62	50	6	37,5	1,25	12,3	✓	0,92 €
MB9	KM9	45	69	56	6	42,5	1,25	15,2	✓	1,05 €
MB10	KM10	50	74	61	6	47,5	1,25	16,0	✓	1,45 €
MB11	KM11	55	81	67	8	52,5	1,25	19,6	-	1,50 €
MB12	KM12	60	86	73	8	57,5	1,50	25,3	✓	1,74 €
MB13	KM13	65	92	79	8	62,5	1,50	29,0	-	2,02 €
MB14	KM14	70	98	85	8	66,5	1,50	30,4	-	2,13 €
MB15	KM15	75	104	90	8	71,5	1,50	35,6	-	2,77 €
MB16	KM16	80	112	95	10	76,5	1,75	46,4	✓	3,48 €
MB17	KM17	85	119	102	10	81,5	1,75	52,4	-	4,13 €
MB18	KM18	90	126	108	10	86,5	1,75	62,3	-	4,68 €
MB19	KM19	95	133	113	10	91,5	1,75	67,0	-	5,65 €
MB20	KM20	100	142	120	12	96,5	1,75	76,5	-	7,37 €
MB22	KM22	110	154	133	12	105,5	1,75	94,0	-	9,17 €
MB24	KM24	120	164	138	14	115,0	2,00	105,0	-	11,87 €
MB26	KM26	130	175	149	14	125,0	2,00	113,0	-	13,91 €
MB28	KM28	140	192	160	15	135,0	2,00	142,0	-	17,77 €
MB30	KM30	150	205	171	15	145,0	2,00	155,0	-	22,87 €

\*Depending on availability - Dimensions in mm