

Conical elasto buffer for foodstuff sector



E-KONBLU

Female mounting

- Rubber buffer suitable for use in the food industry

- FDA compliant

- Materials :

Frame: 316 stainless steel

Cylinder: FDA-compliant blue silicon

- Medium hardness, Shore 55A

- Temperature range : -30 °C to +180 °C

stainless steel

NEW!


For foodstuff industry



Applications

- End stop

- Supporting foot

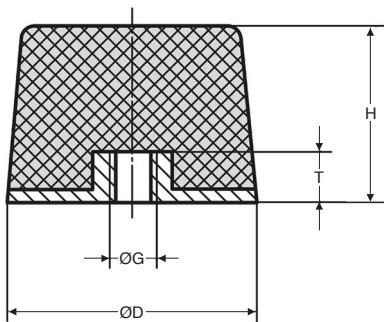

DISCOUNTS

Qty	1+	6+	20+	40+
Disc.	List	10%	-20%	On request

Part number	ØG	ØD	H	T	Stiffness (N/mm)	Load (N)	Price each 1 to 5
E-KON6-25-17/SS/BLU	M6	25	17	6	102	571	
E-KON8-30-15/SS/BLU	M8	30	15	8	185	1036	
E-KON10-50-17/SS/BLU	M10	50	17	10	677	3554	

Dimensions in mm



Conical elasto buffer for foodstuff sector

Male mounting

D-KONBLU

- Rubber buffer suitable for use in the food industry
- FDA compliant
- Materials:
 - Frame: 316 stainless steel
 - Cylinder: FDA-compliant blue silicon
- Medium hardness, Swhore 55A
- Temperature range: -30 °C to +180 °C



Applications

- End stop
- Supporting foot

stainless steel

NEW!

For foodstuff industry

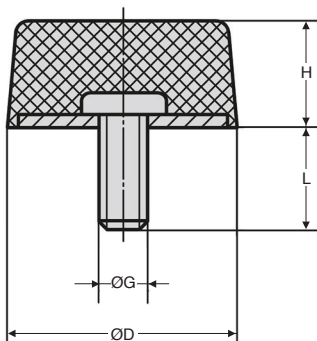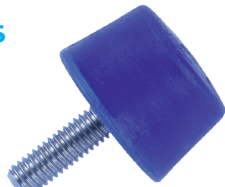

DISCOUNTS

Qty	1+	6+	20+	40+
Disc.	List	10%	-20%	On request

Part number	ØG	ØD	H	L	Stiffness (N/mm)	Load (N)	Price each 1 to 5
D-KON6-25-17/SS/BLU	M6	25	17	18	80	448	
D-KON8-30-15/SS/BLU	M8	30	15	20	265	1530	
D-KON10-50-17/SS/BLU	M10	50	17	28	640	3584	

Dimensions in mm

Our other products



EPE

Wing nuts Hygienic Design®, Narrow



GTC

Belt tensioner, For standard applications



PSPD18

Flexible tube handle, Black PVC



DSF

Slip friction clutch, 4 to 2800 Nm



DTR

Chain idler sprocket, Chain idler sprocket - Plastic



VCMB

Dual-thread screw wood/metal, Stainless steel



CHM63-MOT

Asynchronous AC motorgearboxes 0.37 to 1.5kW, 0.37 to 1.5kW



GBMz

Cylindrical ballscrew nut, Cylindrical nut - Multiple starts



PRF-SCREEN-5

Screen support, Support with 5 axes of rotation



GD01

Double universal joint, Standard duty



BSM

Spring plunger with internal hexagonal socket, steel body, plastic pin



PPG

Indexing plunger with flange, With horizontal mounting flange

Complementary products