




Sta Adjustable **stainless steel** cam lever

With external thread


LACTss

- Element of manual blocking
- Quick fixing
- Materials

Handle: stainless steel Z6CN18.10M, electrolytically polished
 Thrust washer: glass fibre reinforced black plastic PA 6 GF 30
 Hinge pin, threaded stud and washer: polished stainless steel 303

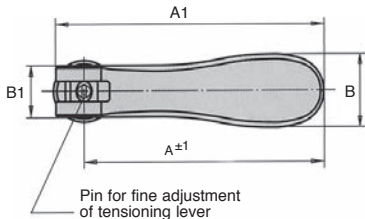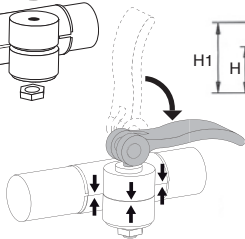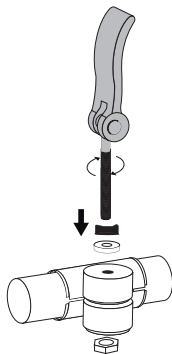

Pin for fine adjustment of tensioning lever

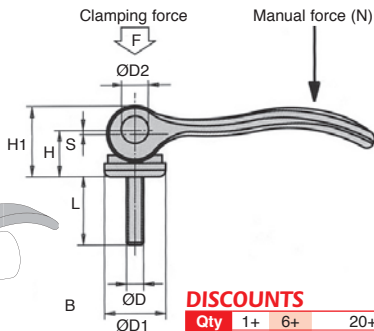

DISCOUNTS

Qty	1+	6+	20+
Disc.	List	-10%	On request

Part number	Thread			B	B1	H	H1	A	A1	Clamping force F (kN)	Manual force N	Stroke S	L	Price each 1 to 5
	ØD	ØD1	ØD2											
LAC-T5/SS	M5	18	9	21,5	15	14,5	22,0	70,4	79,2	4	120	1,2	40	✓ 30,40 €
LAC-T6/SS	M6	18	9	21,5	15	14,5	22,0	70,4	79,2	4	120	1,2	40	✓ 30,40 €
LAC-T8/SS	M8	27	11	33,2	24	18,0	28,5	96,0	108,0	8	350	1,5	50	✓ 41,04 €
LAC-T10/SS	M10	27	11	33,2	24	18,0	28,5	96,0	108,0	8	350	1,5	50	✓ 41,04 €

*Depending on availability - Dimensions in mm

Our other products



SUPss

Self-centering
clamping hub
stainless steel,
Without locknut



BDP1R

Adjustable support
arm, Single clamp



KB_OP

Open precision linear
bearing, Precision -
steel



RFK58B

Hypoid gearbox -
Stainless steel, up to
500 Nm




DOG319

Motor-gearbox 12V
and 24V DC, from 4 to
9 Nm




PP35

 Worm and wheel gear
reducer, from 2.20 to
4.10 Nm



RPPM

 RPP type belt per
metre, RPP14 Steel
cored polyurethane



RIMtce

Locking castor, with
central hole



CQA20

Accessory for
adjustment slide-
system, 20



M2

Worm and wheel set,
Bronze



CHTRP

Single and dual
output gearboxes, Up
to 87,3 Nm



MSP3815

Masterplate®
glueable insert
rectangular,
rectangular with
threaded...

Complementary products



LACM_SS

Stainless steel cam
lever, Female