


- Cold rolled (plastic deformation)
- Conforms to ISO 2901 / 2903
- Capable of transmitting large forces
- Good surface finish
- Material: Half-hard steel XC38
- Thread tolerance: 7e


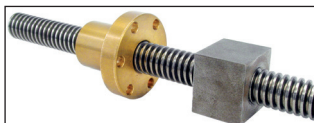


### Uses

- Machine tools
- Lathe main screw

### Options

- Available in lengths up to 6000mm (for diameters 30mm or greater)

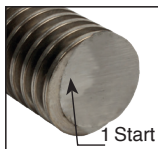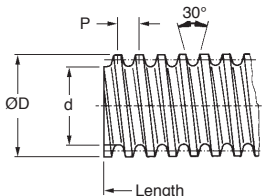

### A DISCOUNTS and AVAILABLE LENGTHS

Qty	1+	10+	20+	40+
Disc.	List	-30%	-40%	On request
Lngt.	1000	2000	3000	6000 mm
Price	List	x2,12	x3,18	On request

### B DISCOUNTS and AVAILABLE LENGTHS


Qté	1+	5+	10+
Rem.	List	-5%	On request
Lngt.	1000	2000	3000 6000 mm
Price	Uni.	x2,12	x3,18 On request

Part number	ØD	Pitch P (mm)	d mini.	Weight (kg/m)	Stock*	Price each per metre	
						1 to 9	40 to 59**
LFM102	10	2	6,89	0,46	✓	7,73 €	4.64
LFM123	12	3	07,68	0,65	✓	10,97 €	6.58
LFM143	14	3	09,68	0,93	✓	14,13 €	8.48
LFM164	16	4	10,47	1,15	✓	17,46 €	10.48
LFM184	18	4	12,47	1,52	✓	21,53 €	12.92
LFM204	20	4	14,47	1,91	✓	25,80 €	15.48
LFM225	22	5	15,29	2,30	✓	30,93 €	18.56
LFM245	24	5	17,27	2,80	✓	35,50 €	21.30
LFM285	28	5	21,27	3,90	✓	49,22 €	29.53
LFM306	30	6	21,56	4,33	✓	53,84 €	32.30
LFM326	32	6	23,56	5,00	✓	61,57 €	36.94
LFM366	36	6	27,56	6,55	✓	46,16 €	On request
LFM407	40	7	30,38	8,00	✓	58,30 €	On request
LFM447	44	7	34,38	9,86	✓	77,09 €	On request
LFM508	50	8	39,17	12,76	✓	95,92 €	On request
LFM609	60	9	47,98	18,65	-	137,79 €	On request
LFM7010	70	10	56,82	25,65	-	188,06 €	On request
LFM8010	80	10	66,82	34,21	-	264,14 €	On request
LFM9012	90	12	74,44	43,00	-	402,70 €	On request
LFM9516	95	16	73,71	45,60	-	392,57 €	On request
LFM10016	100	16	78,71	51,00	-	441,94 €	On request
LFM12016	120	16	98,71	76,00	-	645,20 €	On request

\*Depending on availability - Dimensions in mm

\*\* refer to discounts

- Cold rolled (plastic deformation)
- Conforms to ISO 2901 / 2903
- Capable of transmitting large forces
- Good surface finish
- Material: Half-hard steel XC38
- Thread tolerance: 7e


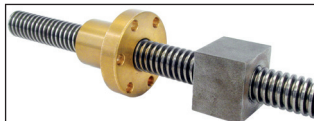


### Uses

- Machine tools
- Lathe main screw

### Options

- Available in lengths up to 6000mm (for diameters 30mm or greater)

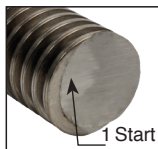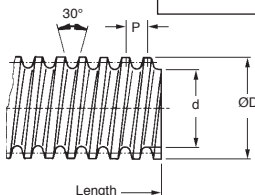

### A DISCOUNTS and AVAILABLE LENGTHS

Qty	1+	10+	20+	40+
Disc.	List	-30%	-40%	On request
Lngt.	1000	2000	3000	6000 mm
Price	Uni.	x2,12	x3,18	On request

### B DISCOUNTS and AVAILABLE LENGTHS

Qté	1+	5+	10+	
Rem.	List	-5%	On request	
Lngt.	1000	2000	3000	6000 mm
Price	Uni.	x2,12	x3,18	On request

Part number	ØD	Pitch P (mm)	d mini.	Weight (kg/m)	Stock*	Price each per metre	
						1 to 9	40 to 59**
LFM102/LH	10	2	6,89	0,46	✓	9,52 €	5,71
LFM123/LH	12	3	07,68	0,65	✓	13,57 €	8,14
LFM143/LH	14	3	09,68	0,93	✓	18,58 €	11,15
LFM164/LH	16	4	10,47	1,15	✓	21,10 €	12,66
LFM184/LH	18	4	12,47	1,52	✓	25,92 €	15,55
LFM204/LH	20	4	14,47	1,91	✓	29,48 €	17,69
LFM225/LH	22	5	15,29	2,30	✓	36,57 €	21,94
LFM245/LH	24	5	17,27	2,80	✓	39,05 €	23,43
LFM285/LH	28	5	21,27	3,90	✓	57,77 €	34,66
LFM306/LH	30	6	21,56	4,33	✓	60,62 €	36,37
LFM326/LH	32	6	23,56	5,00	✓	70,33 €	42,20
LFM366/LH	36	6	27,56	6,55	-	52,29 €	On request
LFM407/LH	40	7	30,38	8,00	-	71,95 €	On request
LFM447/LH	44	7	34,38	9,86	-	102,22 €	On request
LFM508/LH	50	8	39,17	12,76	-	117,32 €	On request
LFM559/LH	55	9	42,98	15,40	-	On request	On request
LFM609/LH	60	9	47,98	18,65	-	178,92 €	On request
LFM7010/LH	70	10	56,82	25,65	-	243,97 €	On request
LFM8010/LH	80	10	66,82	34,21	-	354,53 €	On request
LFM9012/LH	90	12	74,44	43,00	-	On request	On request
LFM9516/LH	95	16	73,71	45,60	-	On request	On request
LFM10016/LH	100	16	78,71	51,00	-	On request	On request
LFM12016/LH	120	16	98,71	76,00	-	On request	On request


\*Depending on availability - Dimensions in mm

\*\* refer to discounts


## Our other products



CHMR30  
Worm and wheel gear reducer, up to 28 Nm

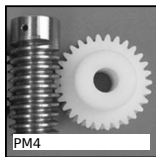

PM4  
Worm and wheel set, Machined plastic (delrin)

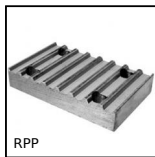

RPP  
Connecting plate for RPP type timing belts, RPP14



DZYSS  
Stainless steel cylindrical stop, stainless steel



AT5P\_AT10P  
Connecting plate for AT type timing belts, AT10



AT5courroie  
AT type timing belt, AT5 Steel cored polyurethane



DHX  
Dowel pin internal thread, Extractable DIN 7979D



PTRSS  
Idler chain sprocket, For hostile environments



G-ECO  
Eco range Spur gear, Steel C45



DTR  
Chain idler sprocket, Chain idler sprocket -



MSP19  
Masterplate® glueable insert



S2B  
Short linear bearing housing, Closed - Slim


## Complementary products



 BFM  
Flanged bronze nut, Bronze - 1 thread



LRM  
Trapezoidal bronze nut, Bronze - 1 thread



VKM  
Square steel nut, Steel - 1 thread



SVT15  
Screwjack with travelling screw, with translating screw